

 

## 嚮導管路

# NEBC-S1H15-E-2.5-N-LE15

料號: 2052917  
將停止供貨的產品

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

FESTO

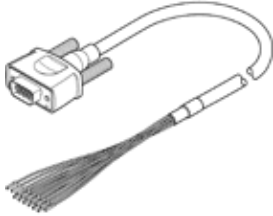

## 技術參數

特性	值
符合標準	DIN 47100
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	15
Electrical connection 1, occupied pins/wires	15
Electrical connection 1, type of mounting	2x screw 4-40 UNC-2A
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	15
Electrical connection 2, occupied pins/wires	15
工作電壓範圍 DC	0 ... 30 V
額定工作電壓 DC	24 V
電纜長度	2.5 m
電纜屬性	適合於拖鏈
Bending radius, fixed cable installation	>= 33 mm
電纜直徑	6.6 mm
電纜結構	18x0,14
導體的額定截面	0.14 mm <sup>2</sup>
導線末端	導線末端套圈
防護等級	IP50
Note on degree of protection	裝配狀態
環境溫度	-30 ... 80 °C
Ambient temperature with flexible cable installation	-30 ... 80 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS
污染程度	3
Material cable sheath	TPE-U(PUR)
電纜外套顏色	灰色