
 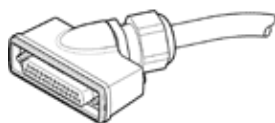


# 連接電纜

## NEBV-C-S1WA25HS-K-2.5-N-LE25-S10

料號: 2265131

FESTO



### 技術參數

特性	值
基於標準	DIN 47100
Cable identification	Without inscription label holder
連接頻率	50
產品重量	460 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	25
Electrical connection 1, occupied pins/wires	25
Electrical connection 1, type of mounting	2 screws 4-40 UNC With seal
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	25
工作電壓範圍 DC	0 ... 30 V
在40°C時的可接受電流負載	2.6 A
保護性接地	還未上市
電纜長度	2.5 m
電纜屬性	標準
Bending radius, fixed cable installation	>= 41 mm
Bending radius, flexible cable installation	>= 122 mm
電纜直徑	10.2 mm
電纜直徑公差	± 0,25 mm
電纜結構	25x0,34
導體的額定截面	0.34 mm <sup>2</sup>
防護等級	IP65 IP67 IP69K
Note on degree of protection	裝配狀態
Special characteristics	Easy to clean
環境溫度	-5 ... 60 °C
Ambient temperature with flexible cable installation	-5 ... 60 °C
儲藏溫度	-20 ... 40 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS
污染程度	3
耐腐蝕等級 CRC	3 - High corrosion stress
Material cable sheath	PVC
電纜外套顏色	灰色
Material housing	PA-加強
外殼顏色	灰色
Material screws	不鏽鋼
Material seals	EPDM
Material electrical contact	Gold-plated bronze
Material insulation	PVC