
 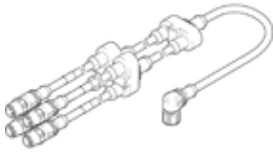


轉接器

NEFV-V12-M12W8-0.6-M12QG5

料號: 4787544

FESTO



技術參數

特性	值
安裝類型	具通孔
產品重量	157 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	圓形
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	8
Electrical connection 1, occupied pins/wires	8
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Analogue output module (green), digital input module (white), analogue input module (yellow), digital output module (red) Controller side
Electrical connection 2, design	圓形
Electrical connection 2, connection type	4x plugs
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, type of mounting	Screw lock
工作電壓範圍 DC	0 ... 30 V
額定工作電壓 DC	24 V
DC工作電壓, 負載電壓	0 ... 30 V
額定DC操作壓力, 負載電壓	24 V
在40°C時的可接受電流負載	2 A
浪湧強度	60 V
電纜長度	0.623 m
電纜屬性	標準
電纜的測試條件	視需求的測試條件
防護等級	IP65 IP67
Note on degree of protection	裝配狀態
環境溫度	-25 ... 80 °C
Ambient temperature with flexible cable installation	-5 ... 80 °C
PWIS conformity	VDMA24364-B1/B2-L
材料備註	符合 RoHS
污染程度	3
耐腐蝕等級 CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
電纜外套顏色	灰色
Material housing	TPE-U(PUR)
外殼顏色	黑色
Material of union nut	Nickel-plated die-cast zinc
Material electrical contact	黃銅 鍍鎳
Material insulation	PP