 



# 編程電纜

## NEBC-S1G9-K-1.5-N-R3G8

料號: 5105645

FESTO

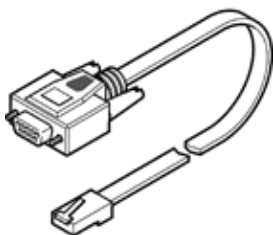

### 技術參數

特性	值
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Electrical connection 1, occupied pins/wires	8
Electrical connection 2, function	Controller side
Electrical connection 2, design	有角的
Electrical connection 2, connection type	插頭
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	RJ45
Electrical connection 2, number of pins/wires	8
Electrical connection 2, occupied pins/wires	8
工作電壓範圍 DC	0 ... 30 V
額定工作電壓 DC	5 V
工作電壓範圍 AC	0 ... 30 V
額定工作電壓, AC	5 V
電纜長度	1.5 m
電纜屬性	標準
防護等級	IP20
Note on degree of protection	裝配狀態
環境溫度	-20 ... 60 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
耐腐蝕等級 CRC	0 - No corrosion stress
外殼顏色	黑色