 



Fieldbus轉接器 FBA-PB-SUB-9-3XM12

料號: 537934
將停止供貨的產品

FESTO

用於連接至 PROFIBUS.

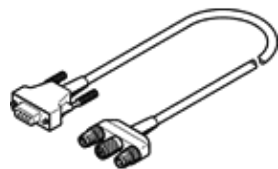

技術參數

特性	值
通訊協定	PROFIBUS
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Electrical connection 1, occupied pins/wires	7
Electrical connection 1, type of mounting	2 screws 4-40 UNC
Electrical connection 2, function	Controller side Incoming bus connection (A), outgoing bus connection (B), power supply bus (C)
Electrical connection 2, design	rund (A), (B), (C)
Electrical connection 2, connection type	Plug connector (A), socket (B), plug connector (C)
Electrical connection 2, cable outlet	Straight (A), (B), (C)
Electrical connection 2, connection technology	M12x1 B(A),(B),M12x1 A(C)
額定工作電壓 DC	24 V
電纜長度	0.11 m
電纜直徑	6 mm
電纜結構	7x0,14 已屏蔽
導體的額定截面	0.14 mm ²
防護等級	IP67
Note on degree of protection	裝配狀態
環境溫度	-5 ... 50 °C
材料備註	含有 PWIS
耐腐蝕等級 CRC	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)