

電源電纜

KPWR-MC-1-SUB-15HC-5

 

料號: 538915

將停止供貨的產品

用於為負載和邏輯部件提供電源連接

Type to be discontinued. Available until 2020. See Support Portal for alternative products.

FESTO

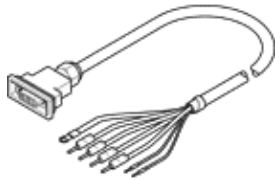

技術參數

| 特性 | 值 |
|--|---|
| Cable identification | Without inscription label holder |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | 有角的 |
| Electrical connection 1, connection type | 插頭插座 |
| Electrical connection 1, cable outlet | 直的 |
| Electrical connection 1, connection technology | Sub-D Mixed |
| Electrical connection 1, number of pins/wires | 7 |
| Electrical connection 1, occupied pins/wires | 6 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | 電纜 |
| Electrical connection 2, connection technology | 開放式終端 |
| Electrical connection 2, number of pins/wires | 6 |
| Electrical connection 2, occupied pins/wires | 6 |
| 工作電壓範圍 DC | 0 ... 24 V |
| 電纜長度 | 5 m |
| 電纜屬性 | 適合於拖鏈 |
| Bending radius, fixed cable installation | >= 50 mm |
| Bending radius, flexible cable installation | >= 100 mm |
| 電纜直徑 | 10 mm |
| 電纜結構 | 2x2,5+2x(2x0,34) 已屏蔽 |
| 導體的額定截面 | 0.34 mm ² 2.5 mm ² |
| 導線末端 | Pin terminal |
| 防護等級 | IP54 |
| Note on degree of protection | 裝配狀態 |
| 環境溫度 | 0 ... 40 °C |
| Ambient temperature with flexible cable installation | -25 ... 60 °C |
| 材料備註 | 含有 PWIS |
| 耐腐蝕等級 CRC | 0 - No corrosion stress |
| Material cable sheath | TPE-U(PUR) |
| Material insulation | TPE-E |