


連接電纜

NEBV-S1W37-E-2.5-LE10

料號: 539240

FESTO

用於多針腳插頭連接至閥島 VTSA 及 VTSA-F, 用於最多 8 個電磁線圈, 具 Sub-D 插頭插座, 10-pin, 適用於電線保護鏈。

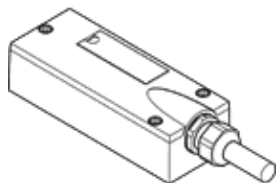

技術參數

| 特性 | 值 |
|--|---|
| 應用領域 | Only for multi-pin plug connection valve terminal VTSA/VTSA-F |
| 符合標準 | DIN 47100 |
| Cable identification | With inscription label holder |
| 產品重量 | 392 g |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | 有角的 |
| Electrical connection 1, connection type | 插頭插座 |
| Electrical connection 1, cable outlet | Angled |
| Electrical connection 1, connection technology | Sub-D |
| Electrical connection 1, number of pins/wires | 37 |
| Electrical connection 1, occupied pins/wires | 10 |
| Electrical connection 1, type of mounting | 3x M4 screws |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | 電纜 |
| Electrical connection 2, connection technology | 開放式終端 |
| Electrical connection 2, number of pins/wires | 10 |
| Electrical connection 2, occupied pins/wires | 10 |
| 工作電壓範圍 DC | 0 ... 30 V |
| 在40°C時的可接受電流負載 | 2 A |
| 浪湧強度 | 1 kV |
| 電纜長度 | 2.5 m |
| 電纜屬性 | Suitable for energy chains |
| 電纜的測試條件 | 視需求的測試條件 |
| Bending radius, fixed cable installation | >= 30 mm |
| Bending radius, flexible cable installation | >= 74 mm |
| 電纜直徑 | 7.4 mm |
| 電纜結構 | 10x0,34 |
| 導體的額定截面 | 0.34 mm ² |
| 防護等級 | IP65 NEMA 4 |
| Note on degree of protection | 裝配狀態 |
| 環境溫度 | -5 ... 50 °C |
| CE 符號 (參見符合的標準) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| 材料備註 | 符合 RoHS |
| 耐腐蝕等級 CRC | 2 - Moderate corrosion stress |
| Material cable sheath | TPE-U(PUR) |
| 電纜外套顏色 | 灰色 |
| Material housing | PA |
| Material insulation | PVC |