 



# Fieldbus轉接器 FBA-CO-SUB-9-M12

料號: 540324

FESTO

用於連接至 CANopen 或 Device Net.

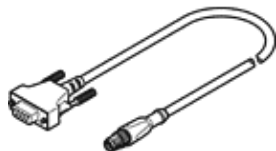

## 技術參數

特性	值
通訊協定	CANopen DeviceNet
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	9
Electrical connection 1, occupied pins/wires	6
Electrical connection 1, type of mounting	2x screw 4-40 UNC-2A
Electrical connection 2, function	Controller side
Electrical connection 2, design	圓形
Electrical connection 2, connection type	插頭
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	5
額定工作電壓 DC	24 V
電纜長度	0.1 m
電纜直徑	6.3 mm
電纜結構	4x0,34 已屏蔽
導體的額定截面	0.34 mm <sup>2</sup>
防護等級	IP67
Note on degree of protection	裝配狀態
環境溫度	-5 ... 50 °C
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
耐腐蝕等級 CRC	0 - No corrosion stress
Material cable sheath	TPE-U(PUR)