


**端板**  
**VMPAL-EPL-FL40-IP40**  
 料號: 560942

FESTO

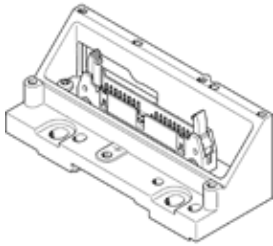

**技術參數**

特性	值
寬度	43 mm
長度	107.3 mm
閥位的最大數量	32
閥島結構	Valve sizes can be mixed
電磁線圈的最大數量	32
Operating pressure MPa	-0.09 ... 1 MPa
操作壓力	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
嚮導壓力	3 ... 8 bar
額定工作電壓 DC	24 V
耐腐蝕等級 CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
防護等級	IP40
Note on degree of protection	裝配狀態
環境溫度	-5 ... 50 °C
產品重量	190 g
Electrical connection 1, function	Multi-pin插頭
Electrical connection 1, connection type	插頭
Electrical connection 1, connection technology	Connection pattern FC
Electrical connection 1, number of pins/wires	40
材料備註	符合 RoHS
Material end plate	壓鑄鋁 PA-加強