


端板
VMPAL-EPR-SP
 料號: 560947

FESTO

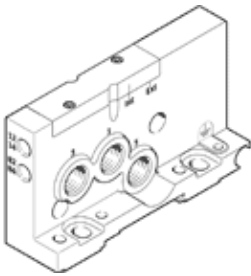

技術參數

特性	值
寬度	28.8 mm
長度	107.3 mm
整合功能	Pilot air selector for choosing the pilot air supply (internal or external)
流量方向	可反向
閥島結構	Valve sizes can be mixed
Operating pressure MPa	-0.09 ... 1 MPa
操作壓力	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
嚮導壓力	3 ... 8 bar
耐腐蝕等級 CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
防護等級	IP65 IP67
Note on degree of protection	裝配狀態
環境溫度	-5 ... 50 °C
產品重量	180 g
嚮導氣口12/14	M7
嚮導排氣口82/84	M7
氣壓連接, 氣口 1	G1/4
氣壓連接, 氣口 3	G1/4
氣壓連接, 氣口 5	G1/4
材料備註	符合 RoHS
Material end plate	壓鑄鋁 PA-加強