


# 插頭插座, 具電纜

## NEBV-H1G2-P-5-N-LE2

料號: 566661

FESTO

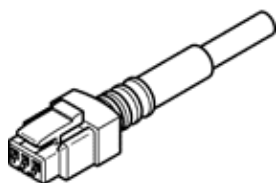

### 技術參數

特性	值
Cable identification	Without inscription label holder
裝配位置	任何
產品重量	70 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Connection pattern H
Electrical connection 1, number of pins/wires	3
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Snap-in locking
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
工作電壓範圍 DC	0 ... 60 V
在40°C時的可接受電流負載	3 A
電纜長度	5 m
電纜屬性	用於靜態應用
電纜直徑	3.4 mm
電纜結構	2x0,14
導體的額定截面	0.14 mm <sup>2</sup>
導線末端	Sheath removed Cut off bluntly
防護等級	IP40
Note on degree of protection	裝配狀態
環境溫度	-5 ... 60 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS
Material cable sheath	TPE-U(PUR)
電纜外套顏色	灰色
Material housing	POM
外殼顏色	黑色
Material electrical contact	銅合金 經過電鍍
Material insulation	PVC