
 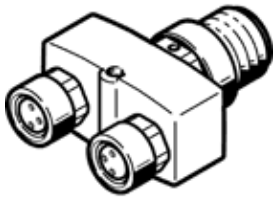


分氣塊

NEDY-L2R1-V1-M8G3-N-M12G4

料號: 8005311

FESTO



技術參數

特性	值
基於標準	EN 61076-2-101 EN 61076-2-104
設計結構	Y-distributor without cable
Distributor type	2 to 1
Cable identification	Without inscription label holder
安裝類型	With through-hole for M2 screw 具配件
產品重量	20 g
Electrical connection 1, function	Controller side
Electrical connection 1, design	圓形
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	M12x1, A-coded in accordance with EN 61076-2-101
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 2, function	Field device side
Electrical connection 2, design	圓形
Electrical connection 2, connection type	2x 插座
Electrical connection 2, cable outlet	直的
Electrical connection 2, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 2, number of pins/wires	3
Electrical connection 2, occupied pins/wires	3
工作電壓範圍 DC	0 ... 30 V
工作電壓範圍 AC	0 ... 30 V
在40°C時的可接受電流負載	3 A
浪湧強度	0.8 kV
防護等級	IP65 IP68 IP69K
環境溫度	-25 ... 85 °C
Note on ambient temperature	-10 ... 40 °C when mounted via through-hole
儲藏溫度	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS 不含鹵素 Free of phosphoric acid ester
污染程度	3
耐腐蝕等級 CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PUR)
電纜外套顏色	灰色
Material housing	PC TPE-U(PUR)
外殼顏色	黑色
Material of union nut	鍍鎳黃銅
Material seals	NBR
Material electrical contact	Gold-plated copper alloy
Material threaded sleeve	鍍鎳黃銅