


surface light SBAL-C6-A-W

料號: 8031158
將停止供貨的產品

FESTO

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

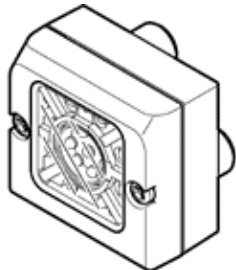

技術參數

特性	值
CE 符號 (參見符合的標準)	根據 EU-EMV 指導原則 in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
授權	RCM Mark
工作距離	100 - 300 mm
Lighting type	Panel light
光的類型	白色 LED Clear
Wavelength	410 - 750 nm
電氣連接	12-pin 2x M12 插頭
Trigger level	Level 10 V ... UB
額定工作電壓 DC	24 V
容許的電壓波動	+/- 10 %
殘餘波動	10 %
Current consumption during continuous operation	80 mA
Current consumption during flash operation	200 mA
Maximum number of devices connectable in series	4
極性保護	用於所有電接口
Ambient temperature during continuous operation	0 ... 50 °C
Ambient temperature during flash operation	0 ... 50 °C
儲藏溫度	-20 ... 60 °C
防護等級	IP67
PWIS conformity	VDMA24364-B2-L
產品重量	60 g
安裝類型	夾在鳩尾槽中 具配件
Material housing	ABS - 強化
材料備註	符合 RoHS