


 
## 連接電纜

### NEBS-SM16G24-K-5-N-LE24

料號: 8048653  
將停止供貨的產品

FESTO

Type to be discontinued. Available until 2025. See Support Portal for alternative products.

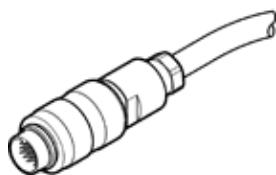

## 技術參數

特性	值
基於標準	EN 61076-2-106
符合標準	DIN 47100
Cable identification	Without inscription label holder
產品重量	745 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	圓形
Electrical connection 1, connection type	插頭
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	M16x0,75
Electrical connection 1, number of pins/wires	24
Electrical connection 1, occupied pins/wires	24
Electrical connection 1, type of mounting	Screw lock
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	電纜
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	25
Electrical connection 2, occupied pins/wires	24
工作電壓範圍 DC	30 V
在40°C時的可接受電流負載	1 A
浪湧強度	500 V
電纜長度	5 m
電纜屬性	標準
Bending radius, fixed cable installation	> 51 mm
Bending radius, flexible cable installation	> 127.5 mm
電纜直徑	8.5 mm
電纜結構	25x0,14
導體的額定截面	0.14 mm <sup>2</sup>
導線末端	Cut off bluntly
防護等級	IP67
環境溫度	-30 ... 70 °C
Ambient temperature with flexible cable installation	-5 ... 70 °C
CE 符號 (參見符合的標準)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
材料備註	符合 RoHS
污染程度	1
Material cable sheath	PVC
電纜外套顏色	灰色
Material housing	PA
Material screw-type lock	Nickel-plated brass
Material electrical contact	Brass, gold-plated
Material insulation	PVC