


真空產生器 OVEL

料號: 8049045

FESTO

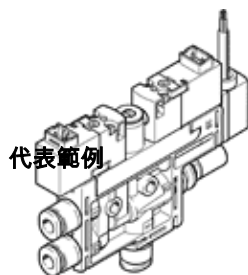

代表範例

技術參數

整體數據表 – 個別數值取決於您的配置。

特性	值
額定尺寸, 拉伐爾噴嘴	0.45 ... 0.95 mm
裝配位置	任何
排放器特性	高吸氣量 高度真空 標準
過濾等級	40 µm
手動控制	推力
整合功能	Ejector pulse, electrical 流量控制閥 Pressure sensor Pressure transmitter 電控開關閥 過濾器 開放式消音器
設計結構	T-形
切換元件功能	N/C 或 N/O 接點, 可切換
閥功能	已關閉
Nominal operating pressure	0.4 MPa
額定操作壓力	4 bar
Nominal operating pressure (psi)	58 psi
工作電壓範圍 DC	21.6 ... 26.4 V
循環功率	100 %
開關輸出	PNP/NPN, 可切換
線圈的特性參數	24 V DC: 1 W
授權	c UL us - Listed (OL)
CE 符號 (參見符合的標準)	根據 EU-EMV 指導原則
UKCA marking (see declaration of conformity)	To UK instructions for EMC
操作介質	壓縮空氣符合 ISO8573-1:2010 [7:4:4]
注意: 操作和嚮導介質	潤滑操作不可行
耐腐蝕等級 CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
介質溫度	0 ... 50 °C
防護等級	IP40
環境溫度	0 ... 50 °C
產品重量	39 ... 100 g
Pressure measurement range	-0.1 ... 0.1 MPa
壓力測量範圍	-1 ... 1 bar
Pressure measurement range	-14.5 ... 14.5 psi
氣壓連接, 氣口 1	共通線路 For tubing outside diameter 3 mm For tubing outside diameter 4 mm For tubing outside diameter 6 mm
Material of connecting thread	POM
材料備註	符合 RoHS

特性	值
Material seals	NBR
Material receiver nozzle	POM
Material filter	POM
Material housing	PA-加強
Material screws	鋼
Material transmitter nozzle	鍛造鋁合金