


Line choke CAMF-C6-FD-C6-3A

料號: 8088930

★ Kernprogramm

FESTO

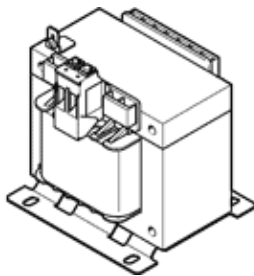

技術參數

| 特性 | 值 |
|--|--------------------------------------|
| 短路強度 | 否 |
| 在40°C時的可接受電流負載 | 6 A |
| 工作電壓範圍 AC | 0 ... 400 V |
| 額定工作電壓, AC | 400 V |
| Nominal inductance | 5.7 mH |
| Nominal inductance tolerance | 10 % |
| 線頻率 | 50 ... 60 Hz |
| 絕緣電壓 | 2,500 V |
| 授權 | ENEC c UL - Recognized (OL) |
| CE 符號 (參見符合的標準) | in accordance with EU RoHS directive |
| PWIS conformity | VDMA24364 zone III |
| 儲藏溫度 | -10 ... 40 °C |
| 防護等級 | IP00 |
| 環境溫度 | -10 ... 40 °C |
| 產品重量 | 2,000 g |
| 安裝類型 | 使用螺栓的安裝板 |
| 材料備註 | 符合 RoHS |
| 裝配位置 | 水平 |
| Electrical connection 1, function | 電源 |
| Electrical connection 1, connection type | 端子條 |
| Electrical connection 1, connection technology | 螺紋介面 |
| Electrical connection 1, number of pins/wires | 2 |
| Electrical connection 1, occupied pins/wires | 2 |
| Electrical connection 1, conductor cross section | 4 mm ² |
| Electrical connection 2, function | 電源 |
| Electrical connection 2, connection type | 端子條 |
| Electrical connection 2, connection technology | 螺紋介面 |
| Electrical connection 2, number of pins/wires | 2 |
| Electrical connection 2, occupied pins/wires | 2 |
| Electrical connection 2, conductor cross section | 4 mm ² |