 



插頭插座 NECV-B2W3L-P-P12

料號: 8105013

FESTO

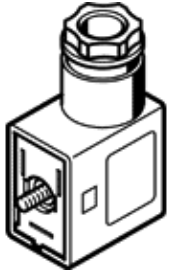

技術參數

特性	值
附加功能	Protective circuit
連接頻率	50
Cable outlet	Angled
Note on cable outlet	180° rotatable
產品重量	19.5 g
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, connection technology	Plug pattern type B to industry standard, 11 mm
Electrical connection 1, number of pins/wires	3
Electrical connection 1, type of mounting	通過M3中心螺絲安裝在電磁閥上
Electrical connection 2, connection technology	螺紋介面
工作電壓範圍 DC	20.4 ... 27.6 V
額定工作電壓 DC	24 V
工作電壓範圍 AC	20.4 ... 27.6 V
額定工作電壓, AC	24 V
在40°C時的可接受電流負載	1 A
浪湧強度	0.8 kV
保護性接地	已可供應
電纜螺紋連接	M15x1,5
電纜直徑	6 ... 8 mm
導體的額定截面	<= 1.5 mm ²
防護等級	IP65
Note on degree of protection	裝配狀態
環境溫度	-20 ... 60 °C
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
污染程度	3
Material housing	PA
外殼顏色	透明
Material screw-type lock	Steel, nickel-plated
Material seals	HNBR
Material electrical contact	Tin-plated brass