


端子條

NECC-L8G5-C1

料號: 8106756

FESTO

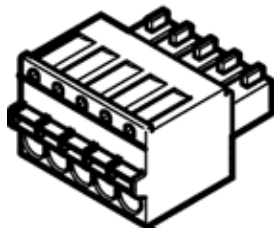

技術參數

特性	值
Cable outlet	直的
產品重量	3.8 g
容器尺寸	1
Electrical connection 1, design	有角的
Electrical connection 1, connection type	插頭插座
Electrical connection 1, connection technology	Manufactured by Assmann WSW components GmbH
Electrical connection 1, number of pins/wires	5
Electrical connection 1, type of mounting	Plug-in
Electrical connection 2, connection technology	壓接式端子
工作電壓範圍 DC	0 ... 300 V
在40°C時的可接受電流負載	8 A
浪湧強度	1.6 kV
Shielding	否
Nominal conductor cross section (AWG)	AWG28 - 16
防護等級	IP20
Note on degree of protection	裝配狀態
環境溫度	-40 ... 115 °C
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
耐腐蝕等級 CRC	1 - Low corrosion stress
Material housing	PA
外殼顏色	黑色