


連接電纜

NEBV-HPG2-PN-0.3-N-LE2

料號: 8122832

FESTO

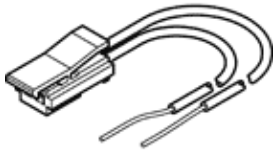

技術參數

特性	值
電磁線圈的最大數量	1
Cable identification	Without inscription label holder
裝配位置	任何
產品重量	2 g
Electrical connection 1, function	Field device side Switching output
Electrical connection 1, design	有角的
Electrical connection 1, connection type	Cable with socket
Electrical connection 1, cable outlet	直的
Electrical connection 1, connection technology	Plug pattern HP
Electrical connection 1, number of pins/wires	2
Electrical connection 1, occupied pins/wires	2
Electrical connection 1, type of mounting	Push-pull with interlock against unintentional pulling
Electrical connection 2, function	電源 Controller side
Electrical connection 2, connection type	2 single wires
Electrical connection 2, connection technology	開放式終端
Electrical connection 2, number of pins/wires	2
Electrical connection 2, occupied pins/wires	2
工作電壓範圍 DC	0 ... 24 V
Shielding	否
操作注意事項	Operate only with external power reduction
電纜長度	0.3 m
電纜屬性	用於靜態應用
Bending radius, fixed cable installation	≥ 11 mm
電纜直徑	0.96 mm
防護等級	IP40
環境溫度	0 ... 50 °C
儲藏溫度	-20 ... 70 °C
PWIS conformity	VDMA24364 zone III
材料備註	符合 RoHS
耐腐蝕等級 CRC	0 - No corrosion stress
Material housing	PEEK
外殼顏色	灰色
Material insulation	PVC