


電接口
VABA-S6-1-PT
 料號: 8152353

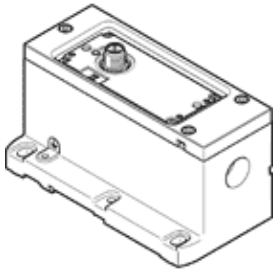

技術參數

特性	值
極性保護	Separate for PS and PL
閥位的最大數量	16
電磁線圈的最大數量	32
傳輸速率	38,4 kbit/s
Intrinsic current consumption at nominal operating voltage for electronics/sensors	Typically 30 mA
Intrinsic current consumption at nominal operating voltage load	Typically 30 mA
額定工作電壓 DC	24 V
殘餘波動	4 Vss
耐腐蝕等級 CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
產品重量	690 g
IO-Link, 連接技術	裝置, 5-pin
IO-Link, protocol	Device V 1.1
IO-Link, 通訊模式	COM2 (38,4 kBaud)
IO-Link, 接口類型	Device B
IO-Link, 接口數	Device 1
IO-Link, process data width OUT	Device 1-4 Byte
IO-Link, 最小周期時間	Device 3,2 ms
最大行列長度	20 m
通訊類型	IO-Link
導體的額定截面	1 mm ²
材料備註	符合 RoHS
Material cover	壓鑄鋁