



MS series service units

Accessories


FESTO

Connecting plate MS4/6-AG...

(order code: AG...)

- Adapter for pneumatic connection
- MS6-AGE for implementing threaded connection G $\frac{3}{4}$

Material:
Aluminium

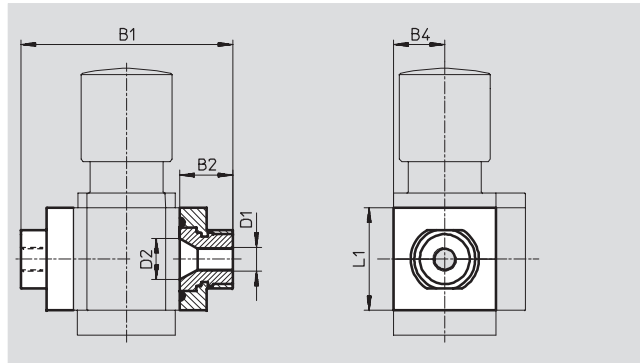


Dimensions and ordering data									
Size	B1	B2	B4	D1	D2	L1	Weight [g]	Part No.	Type
MS4	83.5	21.5	21	G $\frac{1}{8}$	16.8	42	128	526 068	MS4-AGA
				G $\frac{1}{4}$				526 069	MS4-AGB
				G $\frac{3}{8}$				526 070	MS4-AGC
MS6	115	26.5	31	G $\frac{1}{4}$	24	62	300	526 080	MS6-AGB
				G $\frac{3}{8}$				526 081	MS6-AGC
				G $\frac{1}{2}$				526 082	MS6-AGD
				G $\frac{3}{4}$				526 083	MS6-AGE

Connecting plate MS12-AG...

(order code: AG...)

- Adapter for pneumatic connection

Material:
Die-cast aluminium
Free of copper and PTFE

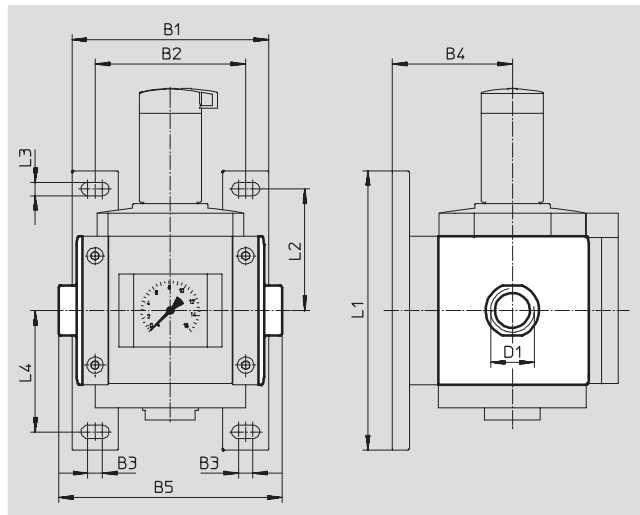

Dimensions and ordering data												
Size	B1	B2	B3	B4	B5	D1	L1	L2	L3	L4	Weight [g]	Part No. Type
MS12	162	124	12	99	184	G1	230	100	11	100	1,300	537 135 MS12-AGF
					184	G1 $\frac{1}{4}$						537 136 MS12-AGG
					184	G1 $\frac{1}{2}$						537 137 MS12-AGH
					196	G2						537 138 MS12-AGI

MS series service units

Accessories

FESTO


Cover cap MS4/6-END

- Can be used to cover the body sides of the first and last module if connecting plates are not used.

Material:

Reinforced polyamide

Free of copper and PTFE

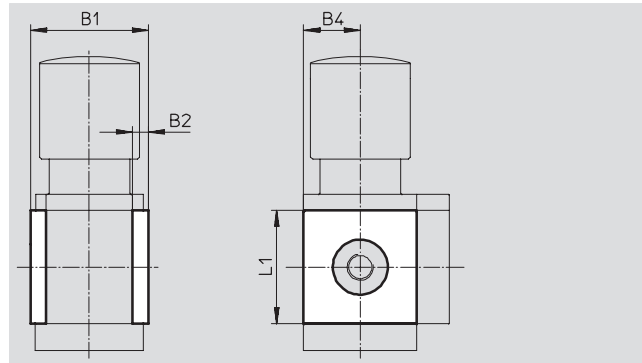

Dimensions and ordering data						
Size	B1	B2	B4	L1	Part No.	Type
MS4	43.6	6	21	42	538 779	MS4-END
MS6	67	8	31	62	538 780	MS6-END

Mounting plate MS6-AEND


(order code: WBE; scope of delivery includes wall mounting plate MS6-WPB)

- In combination with wall mounting plate MS6-WP or MS6-WPB for mounting an individual unit on a wall with direct thread

Material:

Reinforced polyamide

Free of copper and PTFE

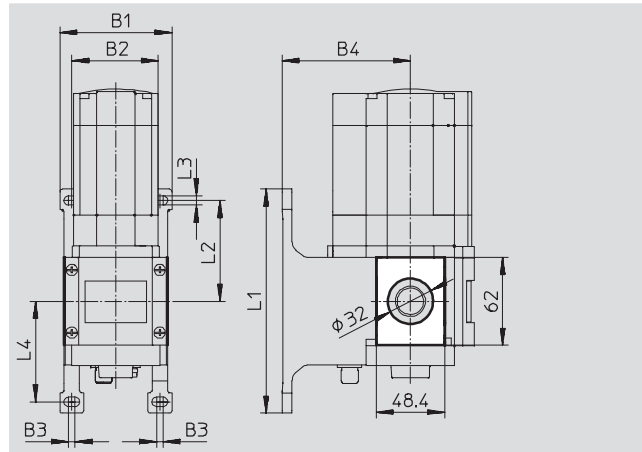

Dimensions and ordering data											
Size	B1	B2	B3	B4	L1	L2	L3	L4	CRC ¹⁾	Weight [g]	Part No. Type
MS6	79	62	4.5	90.5	158	71	6.6	71	2	17	535 408 MS6-AEND  New

1) Corrosion resistance class 2 according to Festo standard 940 070

Components requiring moderate corrosion resistance. Externally visible parts with primarily decorative surface requirements which are in direct contact with a normal industrial environment or media such as coolants or lubricating agents.

MS series service units

Accessories

FESTO


Mounting bracket MS4/6-WB

(order code: WB)

- For wall mounting

Material:

Steel

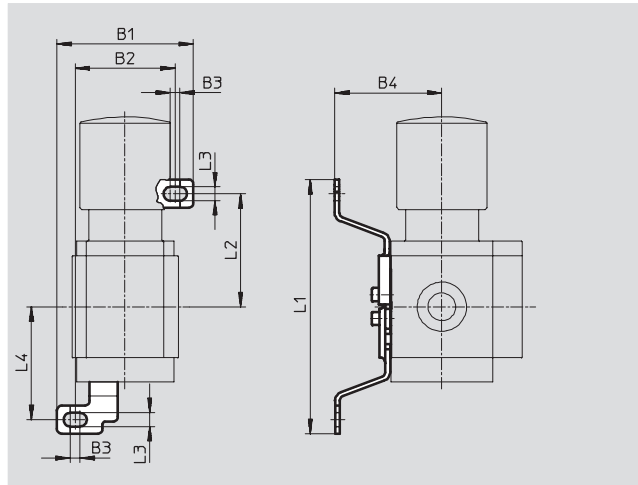

Dimensions and ordering data											
Size	B1	B2	B3	B4	L1	L2	L3	L4	Weight [g]	Part No.	Type
MS4	56.2	41.2	4	44.2	104.6	46.6	5.6	46.5	46	532 185	MS4-WB
MS6	79.4	61.9	4.5	55	157.6	71	6.6	71	121	532 196	MS6-WB


Mounting bracket MS4-WBM

(order code: WBM)

- For wall mounting

Material:

Steel

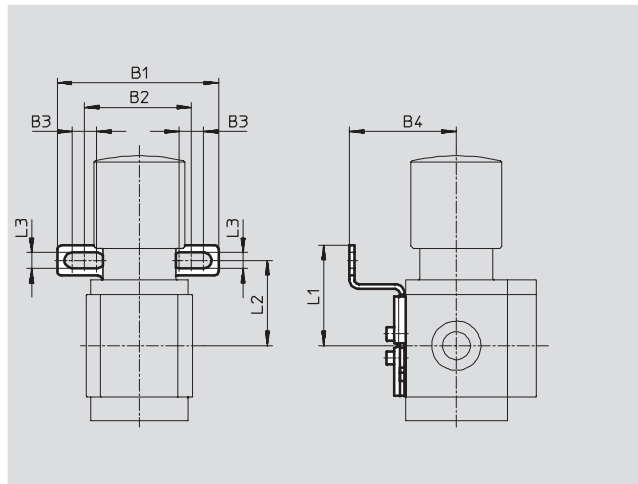

Dimensions and ordering data										
Size	B1	B2	B3	B4	L1	L2	L3	Weight [g]	Part No.	Type
MS4	66.5	44	10	44	41.3	35	6.5	48	526 062	MS4-WBM

MS series service units

Accessories



Mounting bracket MS4/6-WR


(order code: WR)

- For wall mounting
- For filter regulator, pressure regulator

Material:
Steel


Note

The hex nut for attaching components to this bracket must be ordered separately.

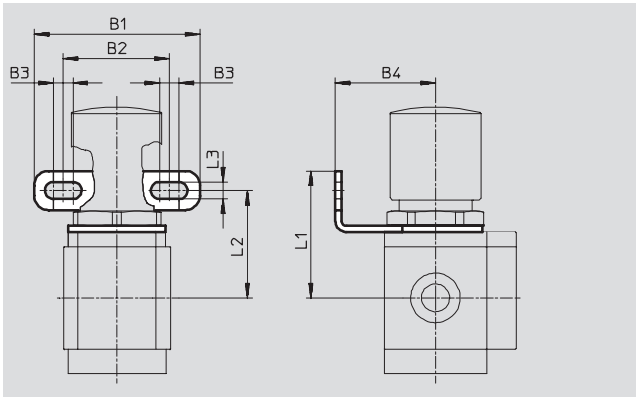


Dimensions and ordering data										
Size	B1	B2	B3	B4	L1	L2	L3	Weight [g]	Part No.	Type
MS4	68	44	8	41	52	44	7	49	526 064	MS4-WR
MS6	70	42	8.2	40	67	57	7.1	90	526 075	MS6-WR

Hex nut MS4/6-WRS

- For front panel mounting
- For attaching components to the mounting bracket MS...-WR

Material:
Aluminium

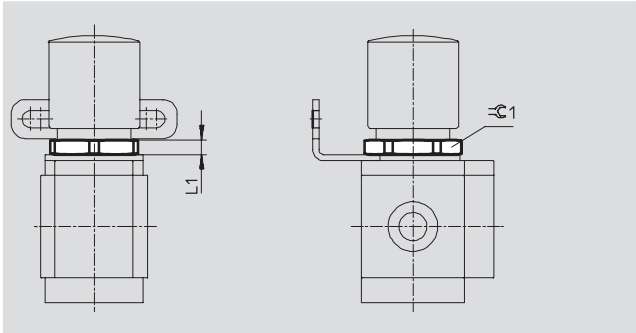

Dimensions and ordering data					
Size	L1	⌀ 1	Weight [g]	Part No.	Type
MS4	6	36	6.9	532 187	MS4-WRS
MS6	7	55	20.9	532 188	MS6-WRS

MS series service units

Accessories

FESTO

Mounting bracket MS4/6-WP...

Clearances for mounting service unit combinations

1 unit

MS4-...: 40 mm

MS6-...: 62 mm

2 units

MS4-...: 80 mm

MS6-...: 124 mm with WP, WPB


138 mm with WPM-2D

1 Mounting bracket WP, WPB or WPM-D


2 Mounting bracket WP, WPB or WPM-2D

Number of units

1 2 3 4 5 6 7 8 9 10

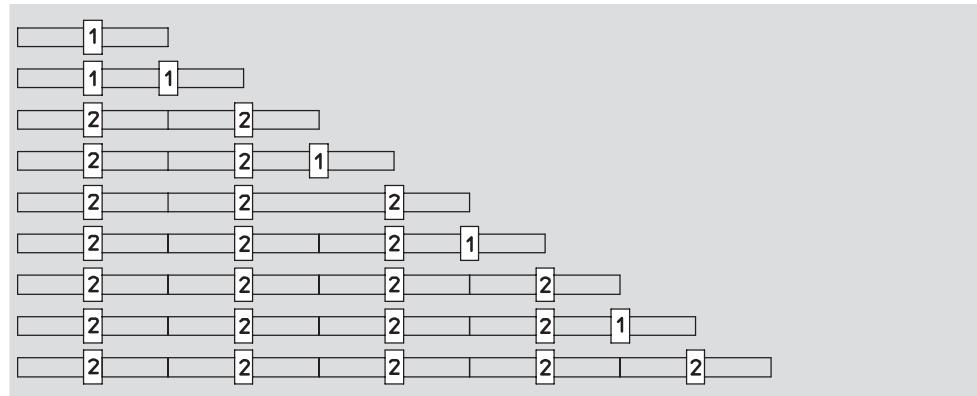

Mounting dimensions

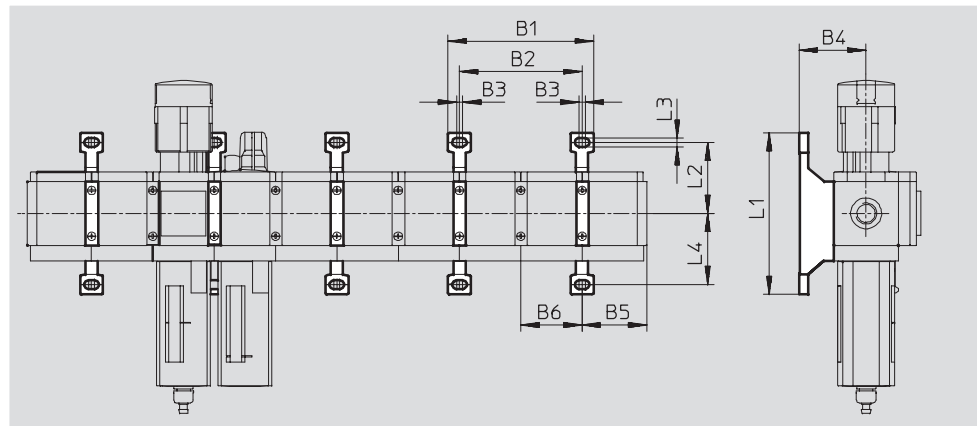

Type	B1	B2	B3	B4	B5	B6	L1	L2	L3	L4
MS4-WP	95.2	80	4	44	41.9	40	106	46.5	5.6	46.7
MS4-WPB				66						
MS4-WPM-...D				44						
MS6-WP	141	124	4.5	54	64.5	62	158	71	6.6	71
MS6-WPB				90.5						
MS6-WPM-...D				54						
	168	138	17.5	54	65.5	69	98.6	41.3		41.3

MS series service units

Accessories

FESTO


Mounting bracket MS4/6-WP

(order code: WP)

- For connecting the modules for wall mounting
- In combination with a connecting plate MS4/6-AG... for mounting an individual unit on a wall
- In combination with mounting plate MS6-AEND or for mounting an individual unit with direct thread on a wall
- For pressure regulator LRB with angled outlet block B... at rear

Material:

Die-cast aluminium

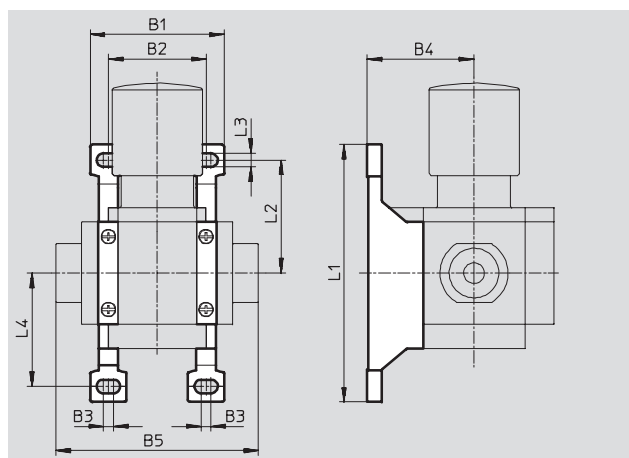

Dimensions and ordering data

Size	B1	B2	B3	B4	B5	L1	L2	L3	L4	Weight [g]	Part No.	Type
MS4	55.2	40.2	4	44	83.4	106	46.5	5.6	46.7	39	532 184	MS4-WP
MS6	79	62	4.5	54	115	158	71	6.6	71	76	532 195	MS6-WP


Mounting bracket MS4/6-WPB

(order code: WPB)

- For connecting the modules for wall mounting
- In combination with a connecting plate MS4/6-AG... for mounting an individual unit on a wall
- In combination with mounting plate MS6-AEND or for mounting an individual unit with direct thread on a wall
- Provides large wall gap for pressure regulator

Material:

Die-cast aluminium

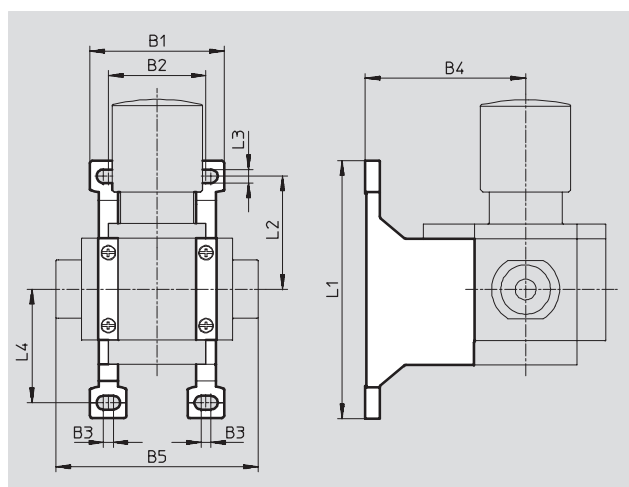

Dimensions and ordering data

Size	B1	B2	B3	B4	B5	L1	L2	L3	L4	Weight [g]	Part No.	Type
MS4	55.2	40.2	4	66	83.4	106	46.5	5.6	46.7	55	526 063	MS4-WPB
MS6	79	62	4.5	90.5	115	158	71	6.6	71	115	526 074	MS6-WPB

MS series service units

Accessories

FESTO




Mounting bracket MS4/6-WPM

(order code: WPM)

- For connecting the modules for wall mounting
- In combination with a connecting plate MS4/6-AG... for mounting an individual unit on a wall
- Speedy attachment and detachment
- For installation of modules with regulating knob pointing downwards

The distance piece D or 2D (designated in the type code) is included in the scope of delivery and ensures the correct clearance

Material:
Die-cast aluminium

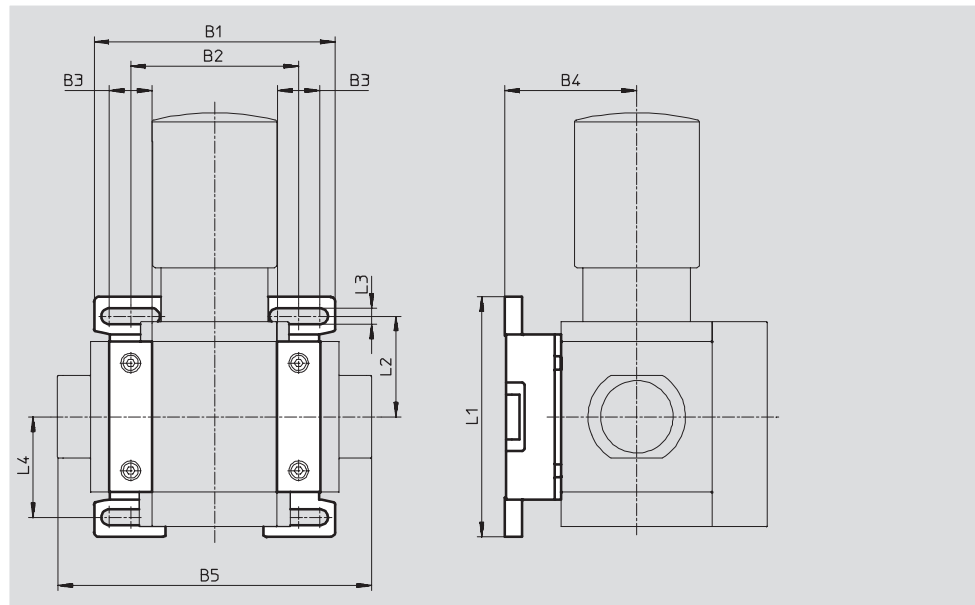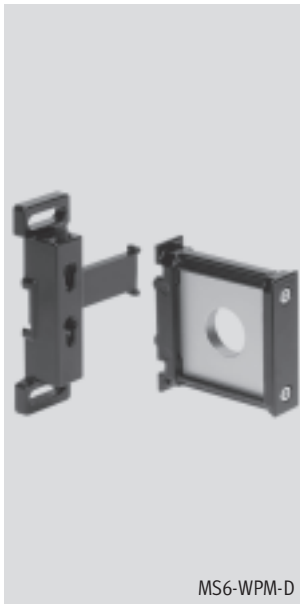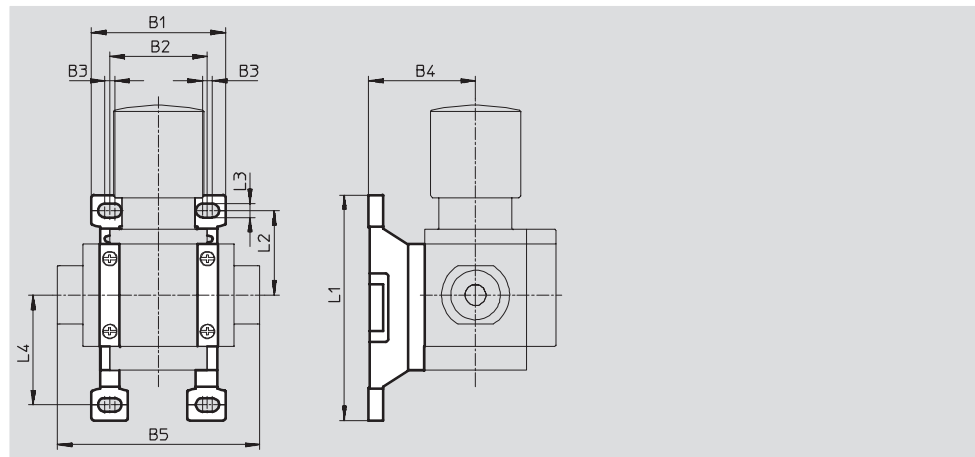

Dimensions and ordering data													
Size	B1	B2	B3	B4	B5	L1	L2	L3	L4	Clearance	Weight [g]	Part No.	Type
MS4	55.2	40	4	44	83.4	92.8	34.8	5.6	45.2	40	45	526 060	MS4-WPM-D
	95.2	80			123.4					80	55	526 061	MS4-WPM-2D
MS6	99	69	17.5	54	129	98.6	41.3	6.6	41.3	62	144	526 073	MS6-WPM-D
	168	138			198					124	154	532 186	MS6-WPM-2D

MS series service units

Accessories

FESTO

Wall mounting plate MS12-WP


(order code: WP)

- For connecting the modules for wall mounting
- In combination with a connecting plate for mounting an individual unit on a wall

Material:

Die-cast aluminium

Free of copper and PTFE

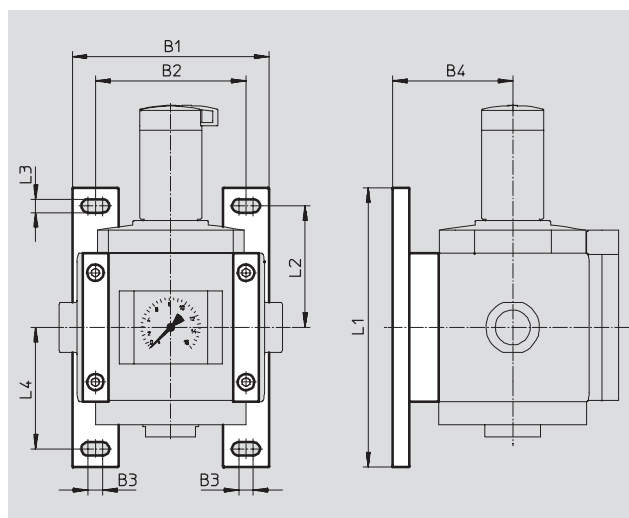

Dimensions and ordering data

Size	B1	B2	B3	B4	L1	L2	L3	L4	Weight [g]	Part No.	Type
MS12	162	124	12	99	230	100	11	100	700	537 133	MS12-WP

Module connector MS...-MV

- For connecting modules

Material:

MS4/6: Stainless steel/polyacetate

MS12: Die-cast aluminium,
free of copper and PTFE



MS4/6



MS12

Ordering data


Size	Weight [g]	Part No.	Type
MS4	36	532 798	MS4-MV
MS6	54	532 799	MS6-MV
MS12	500	537 134	MS12-MV

Module connector MS4/6-MVM

- For installation of modules with regulating knob pointing downwards

Material:

Die-cast aluminium

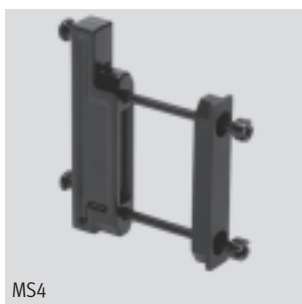

MS4



MS6

Ordering data

Size	Part No.	Type
MS4	532 800	MS4-MVM
MS6	532 801	MS6-MVM

MS series service units

Accessories

FESTO

Filter cartridge MS4/6-LF...



MS...-LFM



MS...-LFP



MS...-LFX

Ordering data				
Size		Grade of filtration [μm]	Part No.	Type
MS4	Micro-filter cartridge	0.01	162 674	MS4/D-MINI-LFM-A
	Fine-filter cartridge	1	162 677	MS4/D-MINI-LFM-B
	Filter cartridge	5	534 501	MS4-LFP-C
	Filter cartridge	40	534 502	MS4-LFP-E
	Active carbon filter cartridge	Residual oil content ≤ 0.003 mg/m ³	532 912	MS4/D-MINI-LFX
MS6	Micro-filter cartridge	0.01	532 909	MS6-LFM-A
	Fine-filter cartridge	1	532 910	MS6-LFM-B
	Filter cartridge	5	534 499	MS6-LFP-C
	Filter cartridge	40	534 500	MS6-LFP-E
	Active carbon filter cartridge	Residual oil content ≤ 0.003 mg/m ³	532 911	MS6-LFX

Filter cartridge MS12-LF...



MS12-LFM-B



MS12-LFM-A



MS12-LFX



Ordering data				
Size		Grade of filtration [μm]	Part No.	Type
MS12	Micro-filter cartridge	0.01	537 146	MS12-LFM-A
	Fine-filter cartridge	1	537 145	MS12-LFM-B
	Filter cartridge	5	537 143	MS12-LFP-C
	Filter cartridge	40	537 144	MS12-LFP-E
	Active carbon filter cartridge	Residual oil content ≤ 0.003 mg/m ³	537 147	MS12-LFX

MS series service units

Accessories

FESTO

Ordering data – Pressure switch PEV					Technical data → www.festo.com	
	Pneumatic connection	Pressure switching point	Electrical connection	Order code	Part No.	Type
	G1/4	Adjustable with visual scale	Plug, square design to DIN EN 175 301, type A	X	161 760	PEV-1/4-SC-0D
	G1/4	Adjustable	Plug, square design to DIN EN 175 301, type A	Y	175 250	PEV-1/4-B-0D
	G1/4	Adjustable	Plug M12x1, 4-pin	M12	192 488	PEV-1/4-B-M12

  Ordering data – Pressure sensor SDE1						Technical data → www.festo.com		
	Pneumatic connection	Electrical output	Electrical connection	Display	Order code	Part No.	Type	
Pressure sensor SDE1 for branching module MS-FRM, pressure measuring range 0 ... 10 bar, relative pressure measurement								
	Female thread G1/8	1 switch output PNP	M8x1, 3-pin	LCD	AD5	192 030	SDE1-D10-G2-H18-C-P1-M8	
		2 switch outputs PNP and 4 ... 20 mA analogue	M12x1, 5-pin	Illuminated LCD	AD6	534 062	SDE1-D10-G2-W18-L-2I-M12	
Pressure sensor SDE1 for direct mounting on the service unit with pressure gauge connection (adapter for pneumatic connection included in scope of delivery), pressure measuring range 0 ... 10 bar, relative pressure measurement								
	Male thread R1/8	1 switch output PNP	M8x1, 3-pin	LCD	–	192 026	SDE1-D10-G2-R18-C-P1-M8	
			M8x1, 3-pin	Illuminated LCD	–	529 970	SDE1-D10-G2-R18-L-P1-M8	
			M12x1, 3-pin	Illuminated LCD	–	534 064	SDE1-D10-G2-R18-L-P1-M12	
		2 switch outputs PNP	M8x1, 4-pin	LCD	–	192 027	SDE1-D10-G2-R18-C-P2-M8	
			M8x1, 4-pin	Illuminated LCD	–	529 971	SDE1-D10-G2-R18-L-P2-M8	
		1 switch output PNP and 0 ... 10 V analogue	M8x1, 4-pin	LCD	–	529 958	SDE1-D10-G2-R18-C-PU-M8	
			M8x1, 4-pin	Illuminated LCD	–	529 972	SDE1-D10-G2-R18-L-PU-M8	
		Male thread R1/4	1 switch output PNP	M8x1, 3-pin	LCD	–	192 028	SDE1-D10-G2-R14-C-P1-M8
				M8x1, 3-pin	Illuminated LCD	–	529 967	SDE1-D10-G2-R14-L-P1-M8
	M12x1, 3-pin			Illuminated LCD	–	534 157	SDE1-D10-G2-R14-L-P1-M12	
	2 switch outputs PNP		M8x1, 4-pin	LCD	–	192 029	SDE1-D10-G2-R14-C-P2-M8	
			M8x1, 4-pin	Illuminated LCD	–	529 968	SDE1-D10-G2-R14-L-P2-M8	
	1 switch output PNP and 0 ... 10 V analogue		M8x1, 4-pin	LCD	–	529 957	SDE1-D10-G2-R14-C-PU-M8	
			M8x1, 4-pin	Illuminated LCD	–	529 969	SDE1-D10-G2-R14-L-PU-M8	


MS series service units

Accessories

FESTO

Ordering data – Angled socket PEV					Technical data → www.festo.com	
	Description	Operating voltage range	Electrical connection	Switching status display	Part No.	Type
	for PEV-1/4-...-OD	15 ... 30 V DC	4-pin	Yellow LED	164 274	PEV-1/4-WD-LED-24
		≤ 230 V AC	4-pin	Yellow LED	164 275	PEV-1/4-WD-LED-230
		≤ 180 V DC				

Ordering data – Plug socket MSSD					Technical data → www.festo.com	
	Description	Operating voltage range	Electrical connection	Type of mounting cable connection	Part No.	Type
	for PEV-1/4-...-OD	≤ 250 V AC/DC	3-pin	Clamping screws	171 157	MSSD-C-4P
	for MS4/6-EE/DE	≤ 250 V AC/DC	3-pin	Clamping screws	151 687	MSSD-EB
			4-pin	Insulation displacement technology	192 745	MSSD-EB-S-M14
	for MS12-EE/DE	≤ 250 V AC/DC	3-pin	Clamping screws	34 583	MSSD-C
			4-pin	Insulation displacement technology	192 748	MSSD-C-S-M16

 Ordering data – Plug socket with cable KMEB/KMC					Technical data → www.festo.com	
	Description	Operating voltage range	Switching status display	Cable length [m]	Part No.	Type
	for MS4/6-EE/DE	24 V DC	LED	2.5	151 688	KMEB-1-24-2,5-LED
		24 V DC	LED	5	151 689	KMEB-1-24-5-LED
		24 V DC	LED	10	193 457	KMEB-1-24-10-LED
		230 V AC	–	2.5	151 690	KMEB-1-230AC-2,5
		230 V AC	–	5	151 691	KMEB-1-230AC-5
	for MS12-EE/DE	24 V DC	LED	2.5	30 931	KMC-1-24DC-2,5-LED
		24 V DC	LED	5	30 933	KMC-1-24DC-5-LED
		24 V DC	LED	10	193 459	KMC-1-24-10-LED
		230 V AC	–	2.5	30 932	KMC-1-230AC-2,5
		230 V AC	–	5	30 934	KMC-1-230AC-5

Ordering data – Illuminating seal MEB-LD/MC-LD				Technical data → www.festo.com	
	Description	Operating voltage range	Part No.	Type	
	for plug socket with cable KMEB and plug socket MSSD-EB	12 ... 24 V DC	151 717	MEB-LD-12-24DC	
		230 V DC/AC ±10%	151 718	MEB-LD-230AC	
	for plug socket with cable KMC and plug socket MSSD-C	12 ... 24 V DC	19 145	MC-LD-12-24DC	
		230 V DC/AC ±10%	19 146	MC-LD-230AC	

Ordering data – Locking clip CPV18-HV				Technical data → www.festo.com	
	Description	Part No.	Type	PU ¹⁾	
	for MS4/6-EE/DE-...-V24			530 056	CPV18-HV
	Cover for manual override, the clip prevents actuation				10

1) Packaging unit quantity

MS series service units

Accessories

FESTO

Ordering data – Plug socket with cable SIM-M8			Technical data → www.festo.com	
	Electrical connection	Cable length [m]	Part No.	Type
	M8x1, 3-pin	2.5	159 420	SIM-M8-3GD-2,5-PU
		5	159 421	SIM-M8-3GD-5-PU
		10	192 964	SIM-M8-3GD-10-PU
	M8x1, 4-pin	2.5	158 960	SIM-M8-4GD-2,5-PU
		5	158 961	SIM-M8-4GD-5-PU
		10	192 965	SIM-M8-4GD-10-PU
	M8x1, 3-pin	2.5	159 422	SIM-M8-3WD-2,5-PU
		5	159 423	SIM-M8-3WD-5-PU
		10	192 965	SIM-M8-3WD-10-PU
	M8x1, 4-pin	2.5	158 962	SIM-M8-4WD-2,5-PU
		5	158 963	SIM-M8-4WD-5-PU
		10	192 965	SIM-M8-4WD-10-PU

Ordering data – Plug socket with cable SIM-M12			Technical data → www.festo.com	
	Electrical connection	Cable length [m]	Part No.	Type
	M12x1, 3-pin	2.5	159 428	SIM-M12-3GD-2,5-PU
		5	159 429	SIM-M12-3GD-5-PU
		10	192 964	SIM-M12-3GD-10-PU
	M12x1, 4-pin	2.5	158 960	SIM-M12-4GD-2,5-PU
		5	158 961	SIM-M12-4GD-5-PU
		10	192 965	SIM-M12-4GD-10-PU
	M12x1, 3-pin	2.5	159 430	SIM-M12-3WD-2,5-PU
		5	159 431	SIM-M12-3WD-5-PU
		10	192 965	SIM-M12-3WD-10-PU
	M12x1, 4-pin	2.5	158 962	SIM-M12-4WD-2,5-PU
		5	158 963	SIM-M12-4WD-5-PU
		10	192 965	SIM-M12-4WD-10-PU

Ordering data – Pressure gauge MA					Technical data → www.festo.com	
	Nominal size	Pneumatic connection	Indicating range		Part No.	Type
			[bar]	[psi]		
	Pressure gauge MA, DIN EN 837-1					Technical data → www.festo.com
	40	G $\frac{1}{4}$	0 ... 16	0 ... 232	183 901	MA-40-16-G $\frac{1}{4}$ -EN
	Pressure gauge MA, DIN EN 837-1, with red-green range					Technical data → www.festo.com
	40	R $\frac{1}{8}$	0 ... 16	–	525 726	MA-40-16-R $\frac{1}{8}$ -E-RG
	50	R $\frac{1}{4}$	0 ... 16	–	525 729	MA-50-16-R $\frac{1}{4}$ -E-RG
	Precision pressure gauge MAP, DIN EN 837-1					Technical data → www.festo.com
	40	R $\frac{1}{8}$	0 ... 1	0 ... 15	161 126	MAP-40-1- $\frac{1}{8}$ -EN
			0 ... 4	0 ... 58	162 842	MAP-40-4- $\frac{1}{8}$ -EN
			0 ... 6	0 ... 87	161 127	MAP-40-6- $\frac{1}{8}$ -EN
			0 ... 16	0 ... 232	161 128	MAP-40-16- $\frac{1}{8}$ -EN

MS series service units


Accessories

FESTO

Ordering data – Silencer U			Technical data → www.festo.com	
	Description	Pneumatic connection	Part No.	Type
	for MS4-EM1/EE	G1/4	6 842	U-1/4-B
	for MS6-EM1/EE	G1/2	6 844	U-1/2-B
	for MS12-EM/EE	G1	151 990	U-1-B

Ordering data – Double nipple ESK				
	Description	Pneumatic connection		Part No. Type
	Adjustable for angular compensation • For retro-fitting pressure switch PEV or pressure sensor SDE1 to branching module MS-FRM	R1/8	R1/4	534 151 ESK-1/8-1/4
		R1/4	R1/4	151 521 ESK-1/4-1/4
			R1/2	534 153 ESK-1/4-1/2

Ordering data – Padlock LRV5-D				
	Description	Weight [g]	Part No.	Type
	for filter or pressure regulators	120	193 786	LRV5-D

 Ordering data – Special oil OFSW				
	Description	Scope of delivery	Part No.	Type
	for lubricators	1 litre	152 811	OFSW-32