

Push-in fittings NPQM

FESTO



Push-in fittings NPQM

Technical data

FESTO

General technical data	
Size	Standard
Design	Push-pull principle
Type of seal on threaded plug	Sealing ring

Materials	
Housing	Nickel-plated brass
Tubing seal	Nitrile rubber
Note on materials	RoHS-compliant

Operating and environmental conditions		
Operating pressure	[bar]	-0.95 ... +16
Operating medium		Filtered compressed air, lubricated or unlubricated
Ambient temperature	[°C]	-20 ... +70
Corrosion resistance class	CRC ¹⁾	1

- 1) Corrosion resistance class 1 according to Festo standard 940 070
Components subject to low corrosion stress. Transport and storage protection. Parts that do not have primarily decorative surface requirements, e.g. in internal areas that are not visible or behind covers

Push-in fittings NPQM

Product range overview

FESTO

Design	Version	Type	Connection D1			Connection D2			→ Page/ Internet	
			M thread	R thread	G thread	Tubing O.D.	Push-in sleeve Ø	Tubing O.D.		Push-in sleeve Ø
Inline	Push-in fitting – Male thread with internal/external hexagon									
		NPQM-D	–	–	G1/8	–	–	4, 6, 8	–	6
					G1/4			6, 8, 10, 12		
					G3/8			8, 10, 12, 14		
					G1/2			10, 12, 14		
	Push-in fitting – Male thread with internal hexagon									
		NPQM-DK	M5	–	–	–	–	4, 6	–	6
			M7					4, 6		
	Push-in fitting – Female thread with external hexagon									
		NPQM-D	–	–	G1/8	–	–	4, 6, 8	–	7
					G1/4			6, 8, 10		
	Push-in connector									
		NPQM-D	–	–	–	4	–	4	–	7
						6		6		
						8		8		
						10		10		
						12		12		
14						14				
Push-in bulkhead connector										
	NPQM-H	–	–	–	4	–	–	–	8	
					6					
					8					
					10					
					12					
Push-in connector with push-in sleeve										
	NPQM-D	–	–	–	4	–	–	6, 8	8	
					6			4, 8, 10, 12, 14		
					8			6, 10, 12, 14		
					10			12, 14		
					12			14		
Push-in sleeve										
	NPQM-D	–	–	–	–	–	–	4	9	
					6			6		
					8			8		
					10			10		
					12			12		
					14			14		

Push-in fittings NPQM

Product range overview

FESTO

Design	Version	Type	Connection D1					Connection D2		→ Page/ Internet
			M thread	R thread	G thread	Tubing O.D.	Push-in sleeve Ø	Tubing O.D.	Push-in sleeve Ø	
L-shape	Push-in L-fitting – Male thread with external hexagon									
		NPQM-L	M5	–	–	–	–	4, 6	–	10
			–		G1/8			4, 6, 8		
					G1/4			6, 8, 10, 12		
					G3/8			8, 10, 12, 14		
					G1/2			10, 12, 14		
	Push-in L-fitting – Male thread with internal hexagon									
		NPQM-LK	M5	–	–	–	–	3, 4	–	11
			–		G1/8			4, 6, 8		
					G1/4			6, 8, 10		
					G3/8			10		
	Push-in L-fitting – Male thread with external hexagon									
		NPQM-LH	M5	–	–	–	–	4, 6	–	12
			–		G1/8			4, 6, 8		
					G1/4			6, 8		
					G3/8			8, 10, 12		
	Two-way multiple distributor – Male thread with internal hexagon									
		NPQM-LFK	–	–	G1/8	–	–	4, 6, 8	–	13
					G1/4			6, 8		
	Push-in L-connector									
		NPQM-L	–	–	–	4	–	4	–	14
						6		6		
						8		8		
						10		10		
						12		12		
						14		14		
Push-in L-connector with push-in sleeve										
	NPQM-L	–	–	–	4	–	–	4	14	
					6			6		
					8			8		
					10			10		

Push-in fittings NPQM

Product range overview

FESTO

Design	Version	Type	Connection D1				Connection D2		→ Page/ Internet	
			M thread	R thread	G thread	Tubing O.D.	Push-in sleeve Ø	Tubing O.D.		Push-in sleeve Ø
T-shape	Push-in T-fitting – Male thread with external hexagon									
		NPQM-T	–	–	G 1/8	–	–	4, 6, 8	–	15
					G 1/4			6, 8, 10		
					G 3/8			8, 10, 12		
					G 1/2			12		
	Push-in T-connector									
		NPQM-T	–	–	–	4	–	4	–	16
						6		6		
						8		8		
						10		10		
12						12				
14						14				
Push-in T-connector with push-in sleeve										
	NPQM-T	–	–	–	4	–	–	4	16	
					6		6			
					8		8			
					10		10			
Y-shape	Push-in Y-connector									
		NPQM-Y	–	–	–	4	–	4	–	17
						6		6		
						8		8		
						10		10		
						12		12		
		NPQM-Y reducing	–	–	–	6	–	4	–	17
						8		6		
						10		8		


Push-in fittings NPQM

Technical data

FESTO

Push-in fitting NPQM-D

Male thread with internal/external hexagon

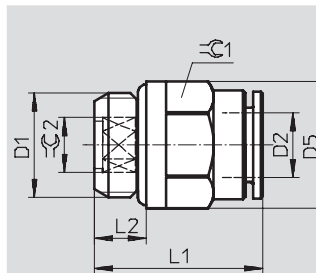


Dimensions and ordering data											
Connection	Nominal size	Tubing O.D.	D5 Ø	L1	L2	≈C 1	≈C 2	Weight/piece	Part No.	Type	PU ¹⁾
D1	[mm]	D2						[g]			
G thread with sealing ring											
G $\frac{1}{8}$	3.0	4	13.0	16.5	5.0	9	3	6.1	558661	NPQM-D-G18-Q4-P10	10
	4.0	6	13.5	19.5	5.0	12	4	9.0	558662	NPQM-D-G18-Q6-P10	10
	6.0	8	13.0	23.5	5.0	13	6	11.4	558663	NPQM-D-G18-Q8-P10	10
G $\frac{1}{4}$	4.0	6	16.0	19.5	6.5	12	4	12.7	558664	NPQM-D-G14-Q6-P10	10
	6.0	8	16.0	21.5	6.5	14	6	13.6	558665	NPQM-D-G14-Q8-P10	10
	8.0	10	16.0	27.5	6.5	15	8	17.4	558666	NPQM-D-G14-Q10-P10	10
	8.0	12	16.0	28.5	6.5	19	8	26.2	558667	NPQM-D-G14-Q12-P10	10
G $\frac{3}{8}$	6.0	8	20.0	21.0	7.0	14	6	20.1	558668	NPQM-D-G38-Q8-P10	10
	8.0	10	20.0	25.0	7.0	16	8	22.6	558669	NPQM-D-G38-Q10-P10	10
	10.0	12	20.0	28.5	7.0	19	10	28.9	558670	NPQM-D-G38-Q12-P10	10
	10.0	14	20.0	32.0	7.0	22	10	37.5	570450	NPQM-D-G38-Q14-P10	1
G $\frac{1}{2}$	8.0	10	25.0	25.5	8.5	16	8	34.5	558671	NPQM-D-G12-Q10-P10	10
	10.0	12	25.0	26.5	8.5	19	10	36.1	558672	NPQM-D-G12-Q12-P10	10
	12.0	14	25.0	32.0	8.5	22	12	42.4	570451	NPQM-D-G12-Q14-P10	1

1) Packaging unit

Push-in fitting NPQM-DK

Male thread with internal hexagon

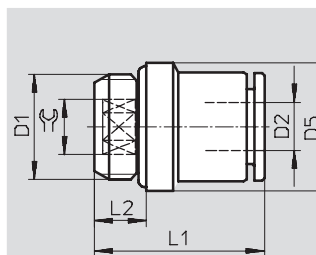

Dimensions and ordering data										
Connection	Nominal size	Tubing O.D.	D5 Ø	L1	L2	≈C	Weight/piece	Part No.	Type	PU ¹⁾
D1	[mm]	D2					[g]			
Metric thread with sealing ring										
M5	2.5	4	8.0	19.0	4.0	2.5	4.6	558657	NPQM-DK-M5-Q4-P10	10
	2.5	6	8.0	22.0	4.0	2.5	8.6	558658	NPQM-DK-M5-Q6-P10	10
M7	3.0	4	9.0	20.0	5.0	3.0	–	558659	NPQM-DK-M7-Q4-P10	10
	3.0	6	9.0	23.0	5.0	3.0	–	558660	NPQM-DK-M7-Q6-P10	10


1) Packaging unit

Push-in fittings NPQM

Technical data

Push-in fitting NPQM-D


Female thread with external hexagon

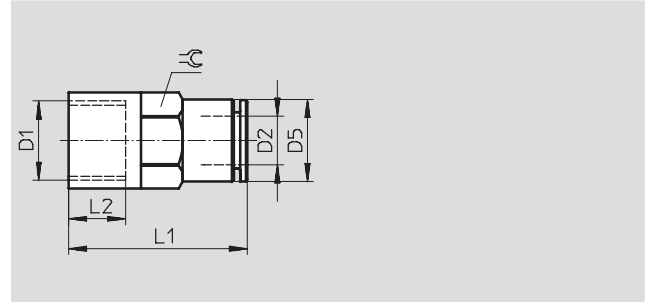

Dimensions and ordering data										
Connection	Nominal size	Tubing O.D.	D5 Ø	L1	L2		Weight/piece [g]	Part No.	Type	PU ¹⁾
D1	[mm]	D2								
G thread										
G $\frac{1}{8}$	3.0	4	9.0	23.5	7.5	9	10.0	558674	NPQM-D-G18F-Q4-P10	10
	5.0	6	12.0	26.0	7.5	12	15.1	558675	NPQM-D-G18F-Q6-P10	10
	7.0	8	14.0	26.0	7.5	14	17.5	558676	NPQM-D-G18F-Q8-P10	10
G $\frac{1}{4}$	5.0	6	12.0	30.0	11.0	12	18.5	558678	NPQM-D-G14F-Q6-P10	10
	7.0	8	14.0	30.0	11.0	14	20.2	558679	NPQM-D-G14F-Q8-P10	10
	9.0	10	16.0	32.0	11.0	16	24.4	558680	NPQM-D-G14F-Q10-P10	10

1) Packaging unit

Push-in connector NPQM-D

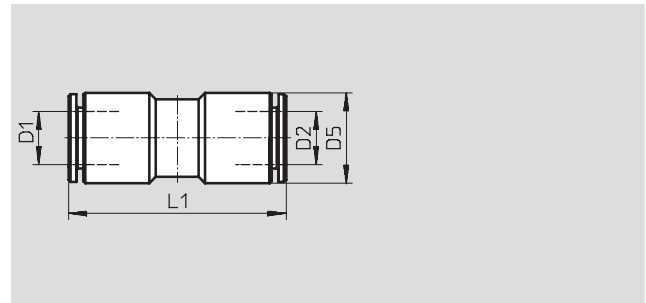

Dimensions and ordering data									
Tubing O.D.	Nominal size	Tubing O.D.	D5 Ø	L1	Weight/piece	Part No.	Type		PU ¹⁾
D1	[mm]	D2			[g]				
4	3.0	4	9.0	28.0	6.8	558760	NPQM-D-Q4-E-P10		10
6	5.0	6	12.0	33.5	15.0	558761	NPQM-D-Q6-E-P10		10
8	7.0	8	14.0	34.0	18.0	558762	NPQM-D-Q8-E-P10		10
10	9.0	10	16.0	38.5	22.5	558763	NPQM-D-Q10-E-P10		10
12	11.0	12	19.0	41.0	36.6	558764	NPQM-D-Q12-E-P10		10
14	13.0	14	22.0	47.0	47.4	570452	NPQM-D-Q14-E-P10		1


1) Packaging unit

Push-in fittings NPQM

Technical data

FESTO

Push-in bulkhead connector NPQM-H

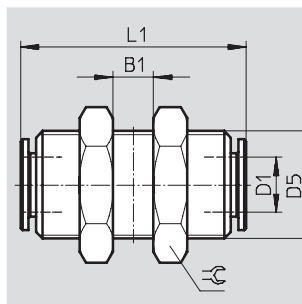


Dimensions and ordering data									
Tubing O.D. D1	Nominal size [mm]	D5	B1	L1		Weight/piece [g]	Part No.	Type	PU ¹⁾
4	3.0	M12x1	11.0	28.0	16	23.5	558806	NPQM-H-Q4-E-P10	10
6	5.0	M14x1	16.0	34.0	18	33.0	558807	NPQM-H-Q6-E-P10	10
8	7.0	M16x1	17.0	34.0	20	39.5	558808	NPQM-H-Q8-E-P10	10
10	9.0	M18x1	19.0	39.0	22	51.5	558809	NPQM-H-Q10-E-P10	10
12	11.0	M20x1	20.0	41.0	24	60.0	558810	NPQM-H-Q12-E-P10	10

1) Packaging unit

Push-in connector NPQM-D

with push-in sleeve

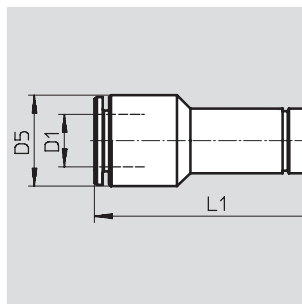


Dimensions and ordering data									
Tubing O.D. D1	Nominal size [mm]	Push-in sleeve Ø D2	D5 Ø	L1	Weight/piece [g]	Part No.	Type	PU ¹⁾	
4	3.0	6	9.0	33.5	7.0	558765	NPQM-D-Q4-S6-P10	10	
	3.5	8	9.0	33.5	10.0	558766	NPQM-D-Q4-S8-P10	10	
6	2.5	4	12.0	35.5	10.0	558767	NPQM-D-Q6-S4-P10	10	
	5.0	8	12.0	35.0	11.5	558768	NPQM-D-Q6-S8-P10	10	
	5.5	10	12.0	36.5	15.5	558769	NPQM-D-Q6-S10-P10	10	
	5.5	12	12.0	35.5	22.2	558770	NPQM-D-Q6-S12-P10	10	
	5.0	14	14.0	37.5	25.0	570457	NPQM-D-Q6-S14-P10	1	
8	4.0	6	14.0	39.5	13.5	558771	NPQM-D-Q8-S6-P10	10	
	7.0	10	14.0	37.0	15.0	558772	NPQM-D-Q8-S10-P10	10	
	7.0	12	14.0	39.0	23.0	558773	NPQM-D-Q8-S12-P10	10	
	7.0	14	14.0	38.5	31.5	570458	NPQM-D-Q8-S14-P10	1	
10	9.0	12	16.0	42.0	20.0	558774	NPQM-D-Q10-S12-P10	10	
	9.0	14	16.0	42.0	29.5	570456	NPQM-D-Q10-S14-P10	1	
12	11.0	14	19.0	43.0	24.0	570459	NPQM-D-Q12-S14-P10	1	

1) Packaging unit

Push-in fittings NPQM

Technical data

Push-in sleeve NPQM-D

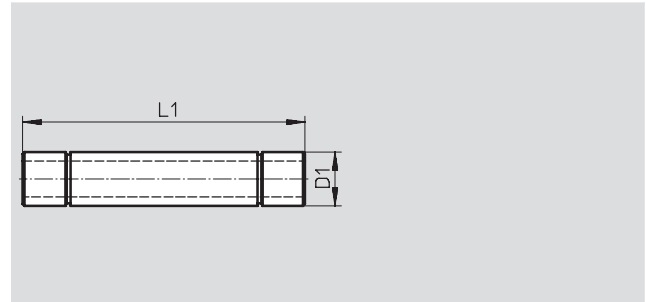

Dimensions and ordering data						
Push-in sleeve Ø D1	Nominal size [mm]	L1	Weight/piece [g]	Part No.	Type	PU ¹⁾
4	2.0	35.0	2.8	558811	NPQM-D-S4-E-P10	10
6	4.0	40.0	5.5	558812	NPQM-D-S6-E-P10	10
8	6.0	42.0	7.5	558813	NPQM-D-S8-E-P10	10
10	8.0	50.0	11.0	558814	NPQM-D-S10-E-P10	10
12	10.0	53.0	14.0	558815	NPQM-D-S12-E-P10	10
14	12.0	54.0	18.5	570455	NPQM-D-S14-E-P10	1

1) Packaging unit


Push-in fittings NPQM

Technical data

FESTO

Push-in L-fitting NPQM-L

Male thread with external hexagon

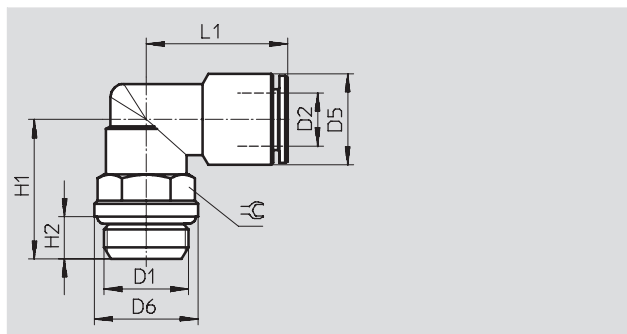

Dimensions and ordering data												
Connection	Nominal size	Tubing O.D.	D5 Ø	D6 Ø	H1	H2	L1	≈ C	Weight/p iece [g]	Part No.	Type	PU ¹⁾
D1	[mm]	D2										
Metric thread with sealing ring												
M5	3.0	4	9.0	8.0	14.0	4.0	17.5	9	8.8	558704	NPQM-L-M5-Q4-P10	10
	3.5	6	12.0	8.0	14.0	4.0	20.5	9	11.9	558705	NPQM-L-M5-Q6-P10	10
G thread with sealing ring												
G1/8	3.0	4	9.0	13.0	18.0	5.0	19.5	13	15.7	558708	NPQM-L-G18-Q4-P10	10
	5.0	6	12.0	13.0	18.0	5.0	22.0	13	18.5	558709	NPQM-L-G18-Q6-P10	10
	5.5	8	14.0	13.0	18.0	5.0	22.5	13	22.0	558710	NPQM-L-G18-Q8-P10	10
G1/4	5.0	6	12.0	16.0	21.5	6.5	22.0	13	21.8	558711	NPQM-L-G14-Q6-P10	10
	5.5	8	14.0	16.0	21.5	6.5	22.5	13	25.3	558712	NPQM-L-G14-Q8-P10	10
	8.5	10	16.0	16.0	22.0	6.5	26.0	16	34.0	558713	NPQM-L-G14-Q10-P10	10
	11.0	12	19.0	16.0	25.5	6.5	28.5	20	58.5	558714	NPQM-L-G14-Q12-P10	10
G3/8	6.0	8	14.0	20.0	25.5	7.0	23.0	16	37.7	558715	NPQM-L-G38-Q8-P10	10
	8.5	10	16.0	20.0	25.5	7.0	26.0	16	39.2	558716	NPQM-L-G38-Q10-P10	10
	11.0	12	19.0	20.0	26.0	7.0	28.5	20	56.1	558717	NPQM-L-G38-Q12-P10	10
	12.0	14	22.0	20.0	26.0	7.0	31.0	20	61.6	570460	NPQM-L-G38-Q14-P10	1
G1/2	8.5	10	16.0	25.0	27.5	8.5	26.0	16	43.2	558718	NPQM-L-G12-Q10-P10	10
	11.0	12	19.0	25.0	30.5	8.5	28.5	20	65.1	558719	NPQM-L-G12-Q12-P10	10
	12.0	14	22.0	25.0	30.5	8.5	31.0	20	69.9	570461	NPQM-L-G12-Q14-P10	1

1) Packaging unit


Push-in fittings NPQM

Technical data

FESTO

Push-in L-fitting NPQM-LK

Male thread with internal hexagon

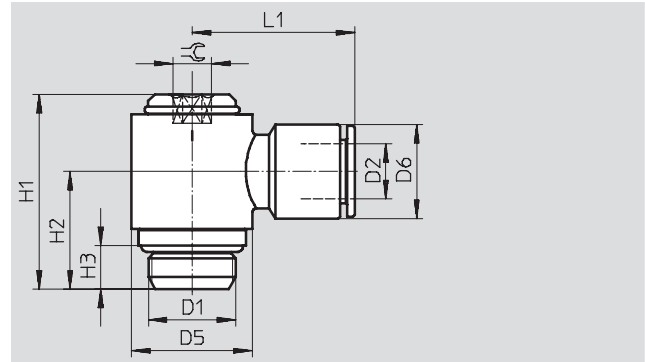

Dimensions and ordering data													
Connection	Nominal size	Tubing O.D.	D5 Ø	D6 Ø	H1	H2	H3	L1	≈	Weight/piece [g]	Part No.	Type	PU ¹⁾
D1	[mm]	D2											
Metric thread with sealing ring													
M5	2.0	3	10.0	7.0	19.0	11.0	4.0	15.0	3	8.1	558816	NPQM-LK-M5-Q3-P10	10
	2.0	4	10.0	9.0	19.0	11.0	4.0	18.5	3	10.1	558817	NPQM-LK-M5-Q4-P10	10
G thread with sealing ring													
G ¹ / ₈	4.0	4	14.0	9.0	25.5	15.0	5.0	20.5	4	22.2	558818	NPQM-LK-G18-Q4-P10	10
	4.0	6	14.0	12.0	25.5	15.0	5.0	22.5	4	24.4	558819	NPQM-LK-G18-Q6-P10	10
	4.0	8	14.0	14.0	25.5	15.0	5.0	23.5	4	25.7	558820	NPQM-LK-G18-Q8-P10	10
G ¹ / ₄	5.5	6	18.0	12.0	29.0	17.5	6.5	24.0	5	39.3	558821	NPQM-LK-G14-Q6-P10	10
	5.5	8	18.0	14.0	29.0	17.5	6.5	24.5	5	39.1	558822	NPQM-LK-G14-Q8-P10	10
	5.5	10	18.0	16.0	29.0	17.5	6.5	27.0	5	43.6	558823	NPQM-LK-G14-Q10-P10	10
G ³ / ₈	7.0	10	22.0	16.0	32.5	19.5	7.0	29.0	6	62.2	558825	NPQM-LK-G38-Q10-P10	10

1) Packaging unit


Push-in fittings NPQM

Technical data

FESTO

Push-in L-fitting NPQM-LH

Male thread with external hexagon

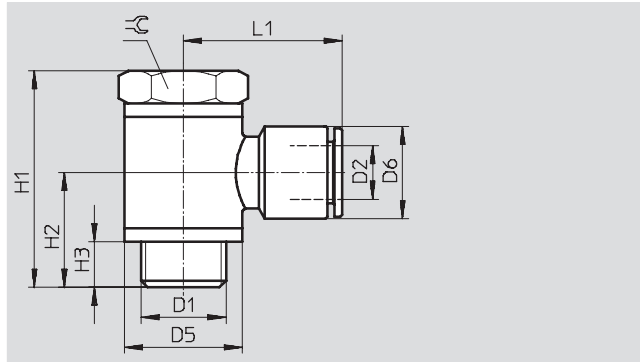

Dimensions and ordering data													
Connection	Nominal size	Tubing O.D.	D5 Ø	D6 Ø	H1	H2	H3	L1	≈	Weight/piece [g]	Part No.	Type	PU ¹⁾
D1	[mm]	D2											
Metric thread with sealing ring													
M5	3.0	4	10.0	9.0	18.5	10.0	4.0	18.5	8	–	558827	NPQM-LH-M5-Q4-P10	10
	3.5	6	10.0	12.0	18.5	10.0	4.0	21.5	8	–	558828	NPQM-LH-M5-Q6-P10	10
G thread with sealing ring													
G1/8	3.0	4	14.0	9.0	27.0	14.0	5.0	20.5	14	–	558829	NPQM-LH-G18-Q4-P10	10
	5.0	6	14.0	12.0	27.0	14.0	5.0	22.5	14	–	558830	NPQM-LH-G18-Q6-P10	10
	6.5	8	14.0	14.0	27.0	14.0	5.0	23.5	14	–	558831	NPQM-LH-G18-Q8-P10	10
G1/4	5.0	6	18.0	12.0	31.5	16.5	6.5	24.0	17	–	558832	NPQM-LH-G14-Q6-P10	10
	6.5	8	18.0	14.0	31.5	16.5	6.5	24.5	17	–	558833	NPQM-LH-G14-Q8-P10	10
G3/8	7.0	8	22.0	14.0	36.0	18.5	7.0	26.5	20	–	558834	NPQM-LH-G38-Q8-P10	10
	8.5	10	22.0	16.0	36.0	18.5	7.0	29.0	20	–	558835	NPQM-LH-G38-Q10-P10	10
	10.5	12	22.0	19.0	36.0	18.5	7.0	29.5	20	–	558836	NPQM-LH-G38-Q12-P10	10

1) Packaging unit


Push-in fittings NPQM

Technical data

FESTO

Multiple distributor NPQM-LFK

Male thread with internal hexagon

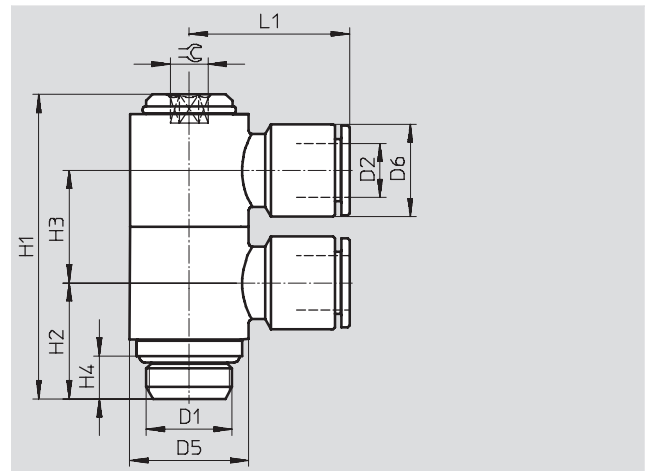

Dimensions and ordering data														
Connection	Nominal size	Tubing O.D.	D5 Ø	D6 Ø	H1	H2	H3	H4	L1	≡	Weight/piece [g]	Part No.	Type	PU ¹⁾
D1	[mm]	D2												
G1/8	4.0	4	14.0	9.0	40.5	15.0	15.0	5.0	20.5	4	40.0	558837	NPQM-LFK-G18-Q4-P10	10
	4.0	6	14.0	12.0	40.5	15.0	15.0	5.0	22.5	4	46.0	558838	NPQM-LFK-G18-Q6-P10	10
	4.0	8	14.0	14.0	40.5	15.0	15.0	5.0	23.5	4	50.0	558839	NPQM-LFK-G18-Q8-P10	10
G1/4	5.5	6	18.0	12.0	46.0	17.5	17.0	6.5	24.0	5	69.5	558840	NPQM-LFK-G14-Q6-P10	10
	5.5	8	18.0	14.0	46.0	17.5	17.0	6.5	24.5	5	69.5	558841	NPQM-LFK-G14-Q8-P10	10


1) Packaging unit

Push-in fittings NPQM

Technical data

FESTO


Push-in L-connector NPQM-L

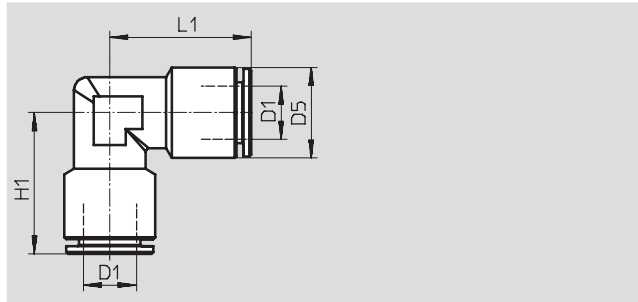

Dimensions and ordering data								
Tubing O.D.	Nominal size	D5 Ø	H1	L1	Weight/piece	Part No.	Type	PU ¹⁾
D1	[mm]				[g]			
4	3.0	9.0	17.5	17.5	9.0	558776	NPQM-L-Q4-E-P10	10
6	5.0	12.0	20.5	20.5	16.5	558777	NPQM-L-Q6-E-P10	10
8	7.0	14.0	22.5	22.5	22.0	558778	NPQM-L-Q8-E-P10	10
10	9.0	16.0	25.0	25.0	29.5	558779	NPQM-L-Q10-E-P10	10
12	11.0	19.0	26.5	26.5	48.5	558780	NPQM-L-Q12-E-P10	10
14	12.0	22.0	31.5	31.5	58.0	570453	NPQM-L-Q14-E-P10	1

1) Packaging unit

Push-in L-connector NPQM-L with push-in sleeve

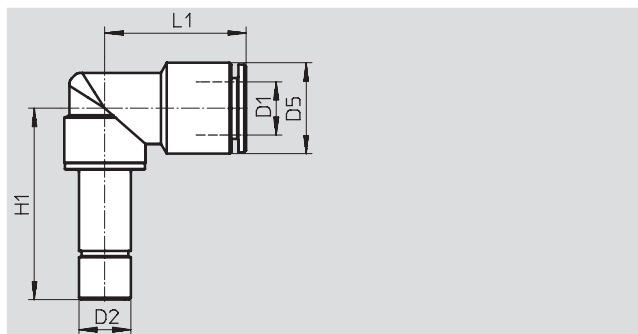

Dimensions and ordering data								
Tubing O.D.	Nominal size	Push-in sleeve Ø	D5 Ø	H1	L1	Weight/piece	Part No.	Type
D1	[mm]	D2				[g]		PU ¹⁾
4	3.0	4	9.0	25.5	19.5	14.0	558781	NPQM-L-Q4-S4-P10
6	5.0	6	12.0	29.5	22.0	17.0	558782	NPQM-L-Q6-S6-P10
8	5.5	8	14.0	29.5	22.5	20.5	558783	NPQM-L-Q8-S8-P10
10	8.5	10	16.0	33.5	26.0	30.0	558784	NPQM-L-Q10-S10-P10

1) Packaging unit


Push-in fittings NPQM

Technical data

FESTO

Push-in T-fitting NPQM-T

Male thread with external hexagon

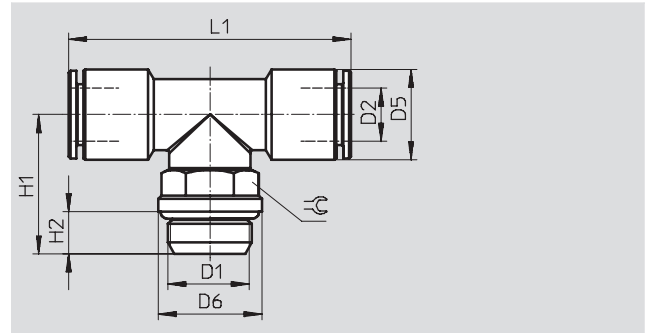

Dimensions and ordering data												
Connection	Nominal size	Tubing O.D.	D5 Ø	D6 Ø	H1	H2	L1	⌀	Weight/piece [g]	Part No.	Type	PU ¹⁾
D1	[mm]	D2										
G thread with sealing ring												
G1/8	3.0	4	9.0	13.0	18.0	5.0	39.0	13	20.2	558736	NPQM-T-G18-Q4-P10	10
	5.0	6	12.0	13.0	18.0	5.0	44.0	13	25.2	558737	NPQM-T-G18-Q6-P10	10
	5.5	8	14.0	13.0	18.0	5.0	45.0	13	30.7	558738	NPQM-T-G18-Q8-P10	10
G1/4	5.0	6	12.0	16.0	21.5	6.5	44.0	13	29.1	558739	NPQM-T-G14-Q6-P10	10
	5.5	8	14.0	16.0	21.5	6.5	45.0	13	33.6	558740	NPQM-T-G14-Q8-P10	10
	8.5	10	16.0	16.0	22.0	6.5	52.0	16	44.4	558741	NPQM-T-G14-Q10-P10	10
G3/8	6.0	8	14.0	20.0	25.5	7.0	46.0	16	46.4	558743	NPQM-T-G38-Q8-P10	10
	8.5	10	16.0	20.0	25.5	7.0	52.0	16	49.7	558744	NPQM-T-G38-Q10-P10	10
	11.0	12	19.0	20.0	26.0	7.0	57.0	20	75.3	558745	NPQM-T-G38-Q12-P10	10
G1/2	11.0	12	19.0	25.0	30.5	8.5	57.0	20	82.0	558747	NPQM-T-G12-Q12-P10	10


1) Packaging unit

Push-in fittings NPQM

Technical data

FESTO


Push-in T-connector NPQM-T

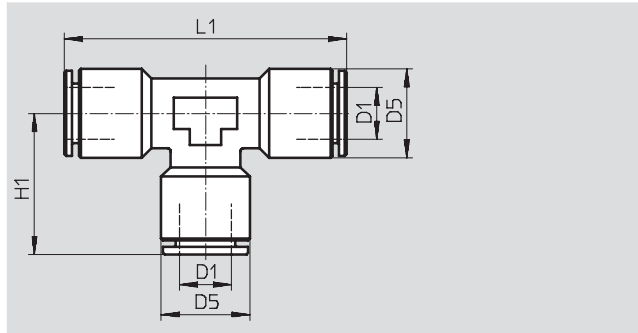

Dimensions and ordering data								
Tubing O.D.	Nominal size	D5 Ø	H1	L1	Weight/piece	Part No.	Type	PU ¹⁾
D1	[mm]				[g]			
4	3.0	9.0	17.5	35.0	12.5	558786	NPQM-T-Q4-E-P10	10
6	5.0	12.0	20.0	40.0	22.5	558787	NPQM-T-Q6-E-P10	10
8	7.0	14.0	21.0	42.0	28.4	558788	NPQM-T-Q8-E-P10	10
10	9.0	16.0	24.5	49.0	39.2	558789	NPQM-T-Q10-E-P10	10
12	11.0	19.0	26.0	52.0	61.3	558790	NPQM-T-Q12-E-P10	10
14	12.0	22.0	30.5	61.0	77.1	570454	NPQM-T-Q14-E-P10	1

1) Packaging unit

Push-in T-connector NPQM-T with push-in sleeve

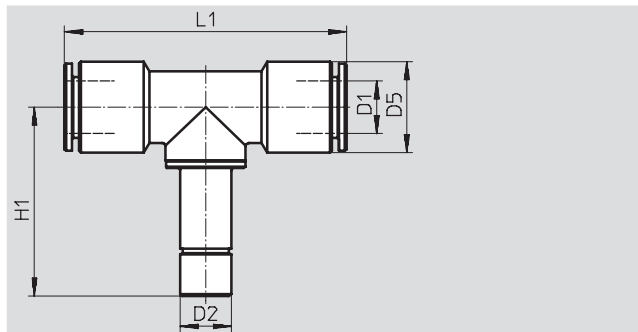

Dimensions and ordering data								
Tubing O.D.	Nominal size	Push-in sleeve Ø	D5 Ø	H1	L1	Weight/piece	Part No.	Type
D1	[mm]	D2				[g]		PU ¹⁾
4	3.0	4	9.0	25.5	39.0	18.5	558791	NPQM-T-Q4-S4-P10
6	5.0	6	12.0	29.5	44.0	24.5	558792	NPQM-T-Q6-S6-P10
8	5.5	8	14.0	29.5	45.0	29.0	558793	NPQM-T-Q8-S8-P10
10	8.5	10	16.0	33.5	52.0	41.0	558794	NPQM-T-Q10-S10-P10


1) Packaging unit

Push-in fittings NPQM

Technical data

FESTO

Push-in Y-connector NPQM-Y

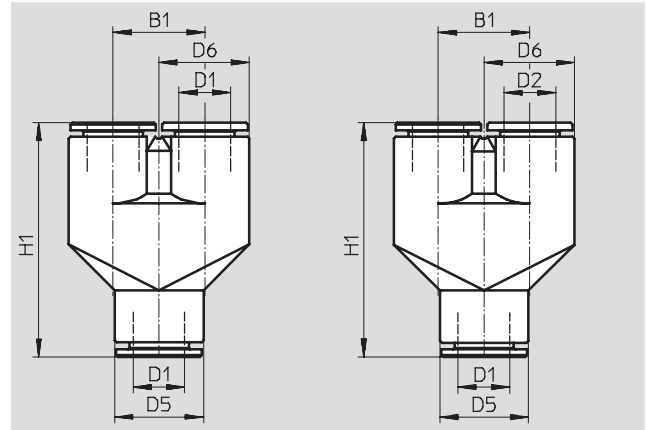

Dimensions and ordering data										
Tubing O.D.	Nominal size	Tubing O.D.	D5	D6	B1	H1	Weight/piece	Part No.	Type	PU ¹⁾
D1	[mm]	D2	Ø	Ø			[g]			
4	3.5	4	9.0	9.25	9.5	29.5	13.5	558798	NPQM-Y-Q4-E-P10	10
6	5.5	6	12.0	12.25	12.5	36.0	32.0	558799	NPQM-Y-Q6-E-P10	10
8	7.5	8	14.0	14.25	14.5	37.5	42.5	558800	NPQM-Y-Q8-E-P10	10
10	9.5	10	16.0	16.25	16.5	44.5	–	558801	NPQM-Y-Q10-E-P10	10
12	11.5	12	19.0	19.25	19.5	49.0	–	558802	NPQM-Y-Q12-E-P10	10
Reducing										
6	3.5	4	12.0	12.25	12.5	36.0	–	558803	NPQM-Y-Q6-Q4-P10	10
8	5.5	6	14.0	14.25	14.5	38.5	–	558804	NPQM-Y-Q8-Q6-P10	10
10	7.5	8	16.0	16.25	16.5	44.0	–	558805	NPQM-Y-Q10-Q8-P10	10

1) Packaging unit

Product Range and Company Overview

A Complete Suite of Automation Services

Our experienced engineers provide complete support at every stage of your development process, including: conceptualization, analysis, engineering, design, assembly, documentation, validation, and production.



Custom Automation Components
Complete custom engineered solutions



Custom Control Cabinets
Comprehensive engineering support and on-site services



Complete Systems
Shipment, stocking and storage services

The Broadest Range of Automation Components

With a comprehensive line of more than 30,000 automation components, Festo is capable of solving the most complex automation requirements.



Electromechanical
Electromechanical actuators, motors, controllers & drives



Pneumatics
Pneumatic linear and rotary actuators, valves, and air supply



PLCs and I/O Devices
PLC's, operator interfaces, sensors and I/O devices

Supporting Advanced Automation... As No One Else Can!

Festo is a leading global manufacturer of pneumatic and electromechanical systems, components and controls for industrial automation, with more than 12,000 employees in 56 national headquarters serving more than 180 countries. For more than 80 years, Festo has continuously elevated the state of manufacturing with innovations and optimized motion control solutions that deliver higher performing, more profitable automated manufacturing and processing equipment. Our dedication to the advancement of automation extends beyond technology to the education and development of current and future automation and robotics designers with simulation tools, teaching programs, and on-site services.

Quality Assurance, ISO 9001 and ISO 14001 Certifications

Festo Corporation is committed to supply all Festo products and services that will meet or exceed our customers' requirements in product quality, delivery, customer service and satisfaction.

To meet this commitment, we strive to ensure a consistent, integrated, and systematic approach to management that will meet or exceed the requirements of the ISO 9001 standard for Quality Management and the ISO 14001 standard for Environmental Management.



© Copyright 2008, Festo Corporation. While every effort is made to ensure that all dimensions and specifications are correct, Festo cannot guarantee that publications are completely free of any error, in particular typing or printing errors. Accordingly, Festo cannot be held responsible for the same. For Liability and Warranty conditions, refer to our "Terms and Conditions of Sale", available from your local Festo office. All rights reserved. No part of this publication may be reproduced, distributed, or transmitted in any form or by any means, electronic, mechanical, photocopying or otherwise, without the prior written permission of Festo. All technical data subject to change according to technical update.



Printed on recycled paper at New Horizon Graphic, Inc., FSC certified as an environmentally friendly printing plant.

Festo North America

Festo Regional Contact Center

5300 Explorer Drive
Mississauga, Ontario L4W 5G4
Canada

USA Customers:

For ordering assistance,

Call: 1.800.99.FESTO (1.800.993.3786)

Fax: 1.800.96.FESTO (1.800.963.3786)

Email: customer.service@us.festo.com

For technical support,

Call: 1.866.GO.FESTO (1.866.463.3786)

Fax: 1.800.96.FESTO (1.800.963.3786)

Email: product.support@us.festo.com

Canadian Customers:

Call: 1.877.GO.FESTO (1.877.463.3786)

Fax: 1.877.FX.FESTO (1.877.393.3786)

Email: festo.canada@ca.festo.com

USA Headquarters

Festo Corporation
395 Moreland Road
P.O. Box 18023
Hauppauge, NY 11788, USA
www.festo.com/us

USA Sales Offices

Appleton

North 922 Tower View Drive, Suite N
Greenville, WI 54942, USA

Boston

120 Presidential Way, Suite 330
Woburn, MA 01801, USA

Chicago

1441 East Business Center Drive
Mt. Prospect, IL 60056, USA

Dallas

1825 Lakeway Drive, Suite 600
Lewisville, TX 75057, USA

Detroit – Automotive Engineering Center

2601 Cambridge Court, Suite 320
Auburn Hills, MI 48326, USA

New York

395 Moreland Road
Hauppauge, NY 11788, USA

Silicon Valley

4935 Southfront Road, Suite F
Livermore, CA 94550, USA

United States



USA Headquarters, East: Festo Corp., 395 Moreland Road, Hauppauge, NY 11788

Phone: 1.631.435.0800; Fax: 1.631.435.8026;

Email: info@festo-usa.com

www.festo.com/us

Canada



Headquarters: Festo Inc., 5300 Explorer Drive, Mississauga, Ontario L4W 5G4

Phone: 1.905.624.9000; Fax: 1.905.624.9001;

Email: festo.canada@ca.festo.com

www.festo.ca

Mexico



Headquarters: Festo Pneumatic, S.A., Av. Ceylán 3, Col. Tequesquahuac,
54020 Tlalneapantla, Edo. de México

Phone: 011 52 [55] 53 21 66 00; Fax: 011 52 [55] 53 21 66 65;

Email: festo.mexico@mx.festo.com

www.festo.com/mx

Central USA

Festo Corporation
1441 East Business
Center Drive
Mt. Prospect, IL 60056, USA
Phone: 1.847.759.2600
Fax: 1.847.768.9480



Western USA

Festo Corporation
4935 Southfront Road,
Suite F
Livermore, CA 94550, USA
Phone: 1.925.371.1099
Fax: 1.925.245.1286



Festo Worldwide

Argentina Australia Austria Belarus Belgium Brazil Bulgaria Canada Chile China Colombia Croatia Czech Republic Denmark
Estonia Finland France Germany Great Britain Greece Hong Kong Hungary India Indonesia Iran Ireland Israel Italy Japan Latvia
Lithuania Malaysia Mexico Netherlands New Zealand Norway Peru Philippines Poland Romania Russia Serbia Singapore
Slovakia Slovenia South Africa South Korea Spain Sweden Switzerland Taiwan Thailand Turkey Ukraine United States Venezuela

www.festo.com