

Push-in fittings CRQS, Quick Star, stainless steel, NPT

FESTO



Push-in fittings CRQS, Quick Star, stainless steel, NPT

FESTO

Technical data

General technical data	
Size	Standard
Design	Push-pull principle
Mounting position	Any


Operating and environmental conditions	
Operating pressure [Psi]	-13.8 ... +203.1
Operating medium	Compressed air in accordance with ISO 8573-1:2010 [7:-:-]
Ambient temperature [°F]	-4 ... +302
Corrosion resistance class CRC ¹⁾	4

1) Corrosion resistance class 4 according to Festo standard 940 070

Components subject to particularly high corrosion stress. Parts used with aggressive media, e.g. in the food or chemical industry. These applications should be supported with special tests with the media if required.

Materials



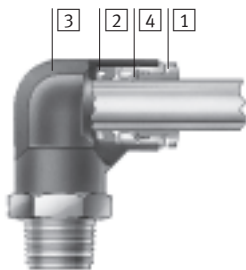




Sectional view



	CRQS, NPT
1 Releasing ring	High-alloy stainless steel
2 Tubing seal	Fluoro elastomer
3 Housing	High-alloy stainless steel
4 Tube retaining claw	High-alloy stainless steel
Note on materials	Contains PWIS (paint wetting impairment substances)
	RoHS-compliant

Push-in fittings CRQS, Quick Star, stainless steel, NPT

Product range overview

Design	Version	Type	Connection D1			Connection D2		→ Page/ Internet	
			NPT thread	Tubing O.D.	Push-in sleeve ∅	Tubing O.D.			
Inline	Push-in fitting – Male thread with internal/external hex								
		CRQS	1/8	–	–	5/32, 1/4	4		
			1/4			1/4, 5/16, 3/8			
			3/8			3/8, 1/2			
			1/2			1/2			
	Push-in connector								
		CRQS-...T	–	5/32	–	–	4		
				1/4					
				5/16					
				3/8					
				1/2					
	Push-in connector with push-in sleeve								
		CRQS-...H	–	–	1/4	5/32	5		
					5/16	1/4			
					3/8	1/4, 5/16			
L-shape	Push-in L-fitting, rotatable 360° – Male thread with external hex								
		CRQSL	1/8	–	–	5/32, 1/4	6		
			1/4			1/4, 5/16, 3/8			
			3/8			3/8, 1/2			
			1/2			1/2			
	Push-in L-connector								
		CRQSL-...T	–	5/32	–	–	6		
				1/4					
				5/16					
				3/8					
				1/2					
	T-shape	Push-in T-fitting, rotatable 360° – Male thread with external hex							
			CRQST	1/8	–	–	5/32, 1/4	7	
				1/4			1/4, 5/16, 3/8		
				3/8			3/8		
Push-in T-connector									
		CRQST-...T	–	5/32	–	–	7		
				1/4					
				5/16					
				3/8					
				1/2					


Push-in fittings CRQS, Quick Star, stainless steel, NPT

Technical data

FESTO

Push-in fitting CRQS


Male thread
with external hex

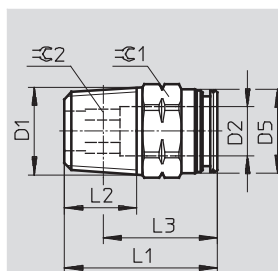

Dimensions and ordering data												
Connection	Nominal size	Tubing O.D.	D5 Ø	L1	L2	L3	$\approx \varnothing 1$	$\approx \varnothing 2$	Weight/piece	Part No.	Type	PU ¹⁾
D1	[inch]	D2							[oz]			
1/8	0.118	5/32	9.5	19.5	8.5	15.4	15/32	1/8	0.342	565318	CRQS-1/8-5/32-U	1
	0.157	1/4	12.0	22.0	8.5	17.9	1/2	5/32	0.388	565319	CRQS-1/8-1/4-U	1
1/4	0.157	1/4	12.0	24.5	13.0	18.7	35/64	5/32	0.628	565320	CRQS-1/4-1/4-U	1
	0.256	5/16	14.0	25.5	13.0	19.7	35/64	1/4	0.575	565321	CRQS-1/4-5/16-U	1
	0.256	3/8	16.0	32.0	13.0	26.2	21/32	1/4	0.896	565322	CRQS-1/4-3/8-U	1
3/8	0.315	3/8	16.0	25.5	13.0	19.4	45/64	5/16	0.917	565323	CRQS-3/8-3/8-U	1
	0.413	1/2	20.0	29.5	13.0	23.4	13/16	13/32	1.118	565324	CRQS-3/8-1/2-U	1
1/2	0.413	1/2	19.5	30.5	17.0	22.4	55/64	13/32	1.633	565325	CRQS-1/2-1/2-U	1

1) Packaging unit

Push-in connector CRQS-...T

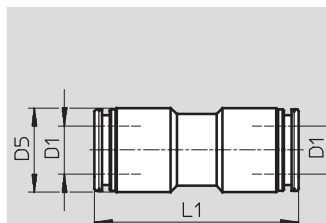

Dimensions and ordering data							
Tubing O.D.	Nominal size	D5 Ø	L1	Weight/piece	Part No.	Type	PU ¹⁾
D1	[inch]			[oz]			
5/32	0.118	9.5	28.0	0.307	565340	CRQS-5/32T-U	1
1/4	0.217	12.0	33.5	0.515	565341	CRQS-1/4T-U	1
5/16	0.256	14.0	34.0	0.695	565342	CRQS-5/16T-U	1
3/8	0.335	16.0	38.5	0.945	565343	CRQS-3/8T-U	1
1/2	0.433	20.0	41.0	1.552	565344	CRQS-1/2T-U	1


1) Packaging unit

Push-in fittings CRQS, Quick Star, stainless steel, NPT

Technical data

FESTO

Push-in connector CRQS-...H
with push-in sleeve

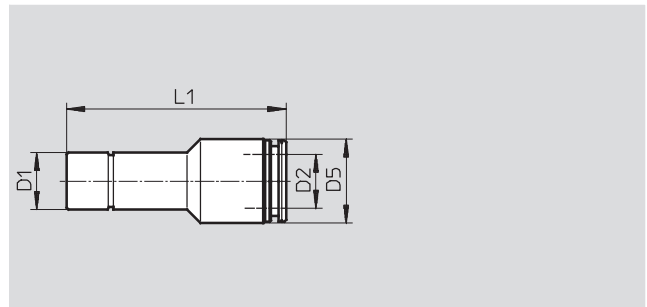

Dimensions and ordering data								
Connection	Nominal size	Tubing O.D.	D5 Ø	L1	Weight/piece	Part No.	Type	PU ¹⁾
D1	[inch]	D2			[oz]			
1/4	0.118	5/32	9.5	31.5	–	565355	CRQS-1/4H-5/32-U	1
5/16	0.197	1/4	12.0	34.5	0.406	565356	CRQS-5/16H-1/4-U	1
3/8	0.217	1/4	12.0	34.5	0.483	565357	CRQS-3/8H-1/4-U	1
	0.256	5/16	14.0	36.5	0.547	565358	CRQS-3/8H-5/16-U	1

1) Packaging unit

Push-in fittings CRQS, Quick Star, stainless steel, NPT

FESTO


Technical data

 
Push-in L-fitting CRQSL

Rotatable 360°

Male thread


with external hex

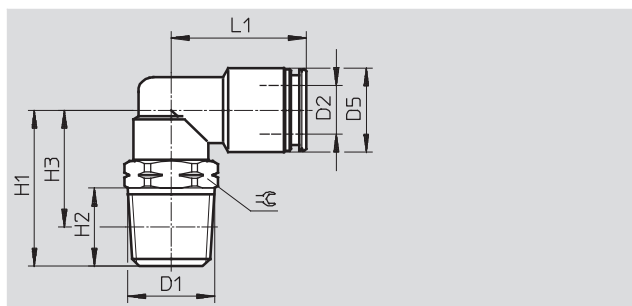

Dimensions and ordering data												
Connection	Nominal size	Tubing O.D.	D5 Ø	H1	H2	H3	L1		Weight/piece	Part No.	Type	PU ¹⁾
D1	[inch]	D2							[oz]			
1/8	0.118	5/32	9.5	18.5	8.5	14.4	17.5	15/32	0.441	565326	CRQSL-1/8-5/32-U	1
	0.217	1/4	12.0	21.0	8.5	16.9	21.5	1/2	0.705	565327	CRQSL-1/8-1/4-U	1
1/4	0.217	1/4	12.0	26.0	13.0	20.2	21.5	35/64	0.97	565328	CRQSL-1/4-1/4-U	1
	0.236	5/16	14.0	26.0	13.0	20.2	22.5	35/64	0.967	565329	CRQSL-1/4-5/16-U	1
	0.335	3/8	16.0	29.0	13.0	23.2	26.0	21/32	1.376	565330	CRQSL-1/4-3/8-U	1
3/8	0.335	3/8	16.0	29.0	13.0	22.9	26.0	45/64	1.517	565331	CRQSL-3/8-3/8-U	1
	0.413	1/2	20.0	32.5	13.0	26.4	28.5	13/16	2.37	565332	CRQSL-3/8-1/2-U	1
1/2	0.413	1/2	20.0	37.0	17.0	28.9	28.5	55/64	2.723	565333	CRQSL-1/2-1/2-U	1

1) Packaging unit

Push-in L-connector CRQSL-...T

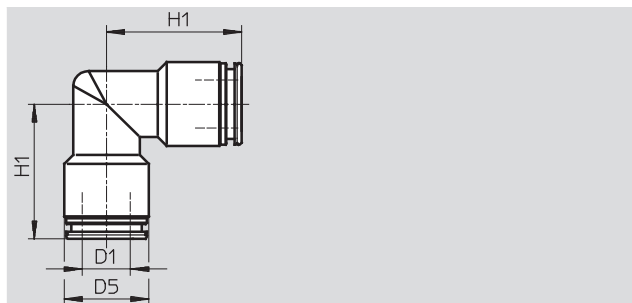

Dimensions and ordering data							
Tubing O.D.	Nominal size	D5 Ø	H1	Weight/piece	Part No.	Type	PU ¹⁾
D1	[inch]			[oz]			
5/32	0.138	9.5	17.5	0.444	565345	CRQSL-5/32-T-U	1
1/4	0.217	12.0	21.0	0.515	565346	CRQSL-1/4-T-U	1
5/16	0.256	14.0	22.5	0.868	565347	CRQSL-5/16-T-U	1
3/8	0.335	16.0	25.5	1.517	565348	CRQSL-3/8-T-U	1
1/2	0.433	20.0	27.5	1.781	565349	CRQSL-1/2-T-U	1


1) Packaging unit

Push-in fittings CRQS, Quick Star, stainless steel, NPT

Technical data

Push-in T-fitting CRQST


Rotatable 360°

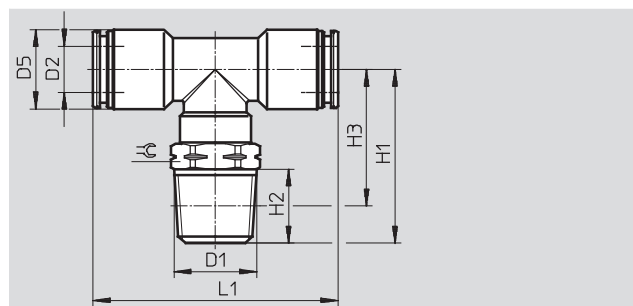Male thread
with external hex


Dimensions and ordering data												
Connection	Nominal size	Tubing O.D.	D5 Ø	H1	H2	H3	L1	⌀	Weight/piece [oz]	Part No.	Type	PU ¹⁾
D1	[inch]	D2										
1/8	0.118	5/32	9.5	22.5	8.5	18.4	35.0	15/32	0.656	565334	CRQST-1/8-5/32-U	1
	0.217	1/4	12.0	25.5	8.5	21.4	42.0	1/2	0.97	565335	CRQST-1/8-1/4-U	1
1/4	0.217	1/4	12.0	30.5	13.0	24.7	42.0	35/64	1.185	565336	CRQST-1/4-1/4-U	1
	0.236	5/16	14.0	30.5	13.0	24.7	43.0	35/64	1.305	565337	CRQST-1/4-5/16-U	1
	0.335	3/8	16.0	32.0	13.0	26.2	51.0	21/32	2.258	565338	CRQST-1/4-3/8-U	1
3/8	0.335	3/8	16.0	32.0	13.0	25.9	51.0	45/64	2.346	565339	CRQST-3/8-3/8-U	1

1) Packaging unit

Push-in T-connector CRQST-...T

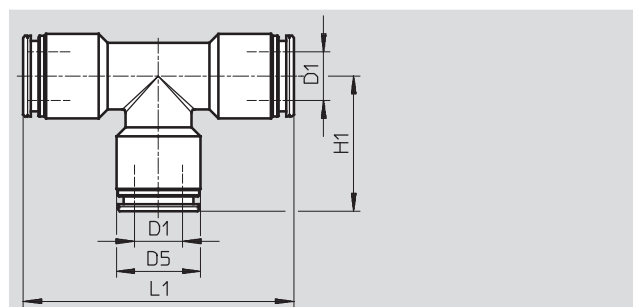

Dimensions and ordering data								
Tubing O.D.	Nominal size	D5 Ø	H1	L1	Weight/piece [oz]	Part No.	Type	PU ¹⁾
D1	[inch]							
5/32	0.138	9.5	17.5	35.0	0.564	565350	CRQST-5/32T-U	1
1/4	0.217	12.0	21.0	42.0	0.988	565351	CRQST-1/4T-U	1
5/16	0.256	14.0	21.5	43.0	1.157	565352	CRQST-5/16T-U	1
3/8	0.335	16.0	25.0	50.0	2.046	565353	CRQST-3/8T-U	1
1/2	0.433	20.0	27.5	55.0	2.469	565354	CRQST-1/2T-U	1

1) Packaging unit

Product Range and Company Overview

A Complete Suite of Automation Services

Our experienced engineers provide complete support at every stage of your development process, including: conceptualization, analysis, engineering, design, assembly, documentation, validation, and production.



Custom Automation Components
Complete custom engineered solutions



Custom Control Cabinets
Comprehensive engineering support and on-site services



Complete Systems
Shipment, stocking and storage services

The Broadest Range of Automation Components

With a comprehensive line of more than 30,000 automation components, Festo is capable of solving the most complex automation requirements.



Electromechanical
Electromechanical actuators, motors, controllers & drives



Pneumatics
Pneumatic linear and rotary actuators, valves, and air supply



PLCs and I/O Devices
PLC's, operator interfaces, sensors and I/O devices

Supporting Advanced Automation... As No One Else Can!

Festo is a leading global manufacturer of pneumatic and electromechanical systems, components and controls for industrial automation, with more than 12,000 employees in 56 national headquarters serving more than 180 countries. For more than 80 years, Festo has continuously elevated the state of manufacturing with innovations and optimized motion control solutions that deliver higher performing, more profitable automated manufacturing and processing equipment. Our dedication to the advancement of automation extends beyond technology to the education and development of current and future automation and robotics designers with simulation tools, teaching programs, and on-site services.

Quality Assurance, ISO 9001 and ISO 14001 Certifications

Festo Corporation is committed to supply all Festo products and services that will meet or exceed our customers' requirements in product quality, delivery, customer service and satisfaction.

To meet this commitment, we strive to ensure a consistent, integrated, and systematic approach to management that will meet or exceed the requirements of the ISO 9001 standard for Quality Management and the ISO 14001 standard for Environmental Management.



© Copyright 2008, Festo Corporation. While every effort is made to ensure that all dimensions and specifications are correct, Festo cannot guarantee that publications are completely free of any error, in particular typing or printing errors. Accordingly, Festo cannot be held responsible for the same. For Liability and Warranty conditions, refer to our "Terms and Conditions of Sale", available from your local Festo office. All rights reserved. No part of this publication may be reproduced, distributed, or transmitted in any form or by any means, electronic, mechanical, photocopying or otherwise, without the prior written permission of Festo. All technical data subject to change according to technical update.



Printed on recycled paper at New Horizon Graphic, Inc., FSC certified as an environmentally friendly printing plant.

Festo North America

Festo Regional Contact Center

5300 Explorer Drive
Mississauga, Ontario L4W 5G4
Canada

USA Customers:

For ordering assistance,

Call: 1.800.99.FESTO (1.800.993.3786)

Fax: 1.800.96.FESTO (1.800.963.3786)

Email: customer.service@us.festo.com

For technical support,

Call: 1.866.GO.FESTO (1.866.463.3786)

Fax: 1.800.96.FESTO (1.800.963.3786)

Email: product.support@us.festo.com

Canadian Customers:

Call: 1.877.GO.FESTO (1.877.463.3786)

Fax: 1.877.FX.FESTO (1.877.393.3786)

Email: festo.canada@ca.festo.com

USA Headquarters

Festo Corporation
395 Moreland Road
P.O. Box 18023
Hauppauge, NY 11788, USA
www.festo.com/us

USA Sales Offices

Appleton

North 922 Tower View Drive, Suite N
Greenville, WI 54942, USA

Boston

120 Presidential Way, Suite 330
Woburn, MA 01801, USA

Chicago

1441 East Business Center Drive
Mt. Prospect, IL 60056, USA

Dallas

1825 Lakeway Drive, Suite 600
Lewisville, TX 75057, USA

Detroit – Automotive Engineering Center

2601 Cambridge Court, Suite 320
Auburn Hills, MI 48326, USA

New York

395 Moreland Road
Hauppauge, NY 11788, USA

Silicon Valley

4935 Southfront Road, Suite F
Livermore, CA 94550, USA

United States



USA Headquarters, East: Festo Corp., 395 Moreland Road, Hauppauge, NY 11788

Phone: 1.631.435.0800; Fax: 1.631.435.8026;

Email: info@festo-usa.com

www.festo.com/us

Canada



Headquarters: Festo Inc., 5300 Explorer Drive, Mississauga, Ontario L4W 5G4

Phone: 1.905.624.9000; Fax: 1.905.624.9001;

Email: festo.canada@ca.festo.com

www.festo.ca

Mexico



Headquarters: Festo Pneumatic, S.A., Av. Ceylán 3, Col. Tequesquahuac,
54020 Tlalnepantla, Edo. de México

Phone: 011 52 [55] 53 21 66 00; Fax: 011 52 [55] 53 21 66 65;

Email: festo.mexico@mx.festo.com

www.festo.com/mx

Central USA

Festo Corporation
1441 East Business
Center Drive
Mt. Prospect, IL 60056, USA
Phone: 1.847.759.2600
Fax: 1.847.768.9480



Western USA

Festo Corporation
4935 Southfront Road,
Suite F
Livermore, CA 94550, USA
Phone: 1.925.371.1099
Fax: 1.925.245.1286



Festo Worldwide

Argentina Australia Austria Belarus Belgium Brazil Bulgaria Canada Chile China Colombia Croatia Czech Republic Denmark
Estonia Finland France Germany Great Britain Greece Hong Kong Hungary India Indonesia Iran Ireland Israel Italy Japan Latvia
Lithuania Malaysia Mexico Netherlands New Zealand Norway Peru Philippines Poland Romania Russia Serbia Singapore
Slovakia Slovenia South Africa South Korea Spain Sweden Switzerland Taiwan Thailand Turkey Ukraine United States Venezuela

www.festo.com