


Distributor block FRZ

FESTO

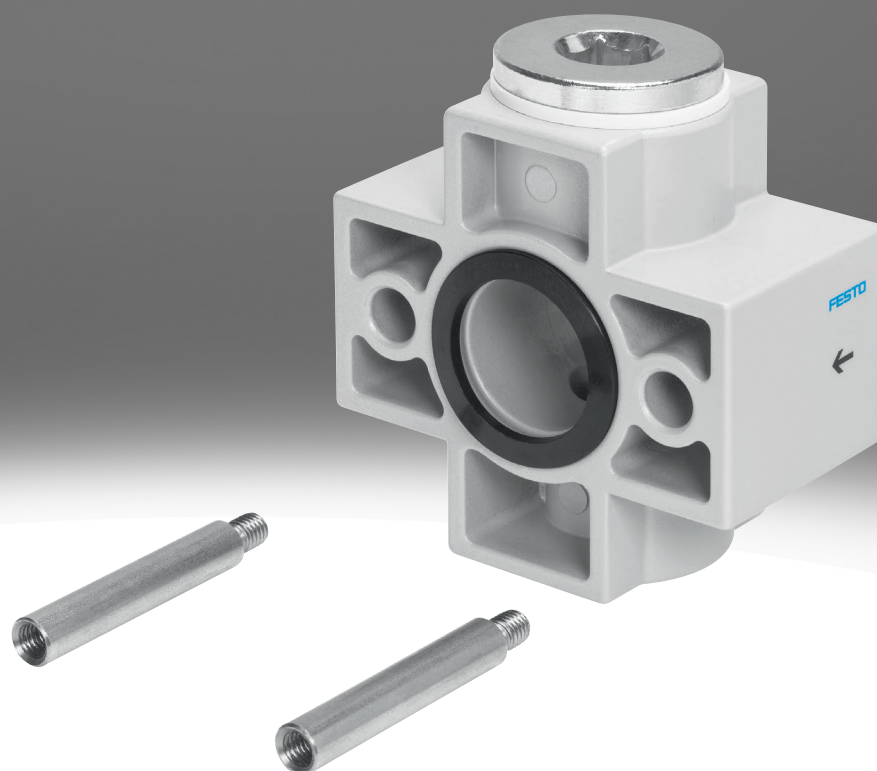

Characteristics

At a glance

Slim air distributor.

- Outlet at top and bottom
- Can be used as an intermediate distributor for varying air qualities

Version

Metal design

Size

Sizes Mini, Midi, Maxi

- Grid dimension: 40 mm; 55 mm; 66 mm

Type code


001	Series	
FRZ	Distributor block	
002	Version	
D	D series, metal	

003	Size	
MINI	Grid dimension 40 mm (without connecting plates)	
MIDI	Grid dimension 55 mm (without connecting plates)	
MAXI	Grid dimension 66 mm (without connecting plates)	
004	Thread type	
NPT	NPT thread	

Datasheet

General technical data	
Mounting position	optional
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L

 
Function



Dimensions

Dimensions – Distributor blocks


Download CAD data www.festo.com

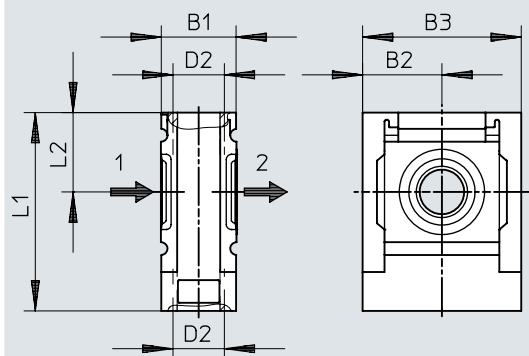

	B1	B2	B3	D2	L1	L2
MS4-FRM-FRZ	20	21	42	G1/4	52,5	21

Ordering data

Distributor block			
	Size	Part no.	Type
	Grid dimension 40 mm (without connecting plates)	162786	FRZ-D-MINI
	Grid dimension 55 mm (without connecting plates)	159592	FRZ-D-MIDI
	Grid dimension 66 mm (without connecting plates)	162787	FRZ-D-MAXI

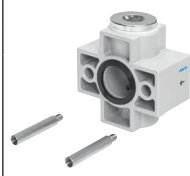Distributor block (NPT – not available in all markets)			
	Size	Part no.	Type
	Grid dimension 40 mm (without connecting plates)	178233	FRZ-D-MINI-NPT
	Grid dimension 55 mm (without connecting plates)	178234	FRZ-D-MIDI-NPT
	Grid dimension 66 mm (without connecting plates)	178235	FRZ-D-MAXI-NPT