


Inscription label

FESTO

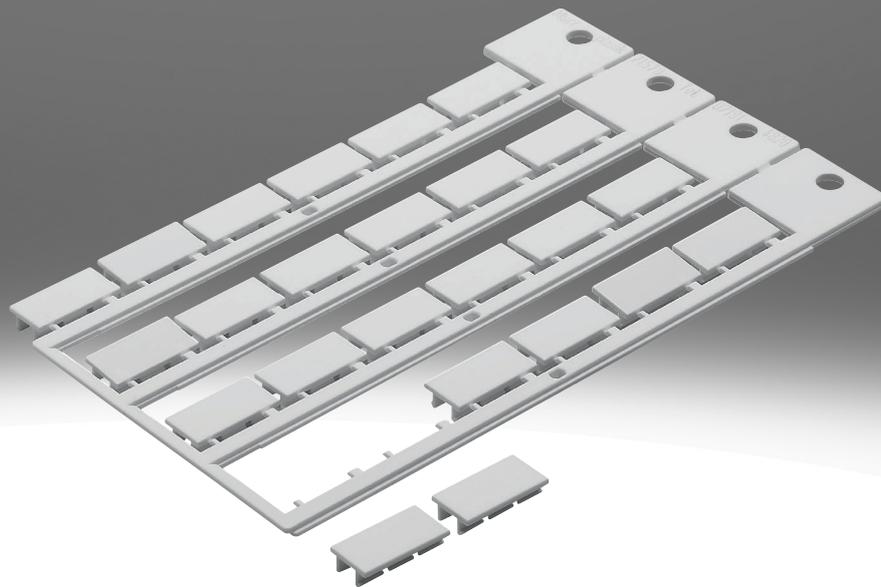

Datasheet

General technical data – Inscription labels for mechanically actuated valves



Size	ø 22.3 mm	ø 30.5 mm	ø 90 mm
Installation diameter	22.3 mm	30.5 mm	90 mm
Height	–	27 mm	–
Length	–	89 mm	–

Materials – Inscription labels for mechanically actuated valves

Size	ø 22.3 mm	ø 30.5 mm	ø 90 mm
Material label	Aluminium		PVC
Note on materials	RoHS-compliant		
LABS (PWIS) conformity	VDMA24364-B1/B2-L		

Operating and environmental conditions – Inscription labels for mechanically actuated valves

Corrosion resistance class CRC ¹⁾	0 - No corrosion stress
---	-------------------------

1) More information www.festo.com/x/topic/crc

General technical data – Inscription labels for identifying the pressure zone separation



Type of mounting	Plug-in
Height	–
Length	–
Product weight	1 g

Materials – Inscription labels for identifying the pressure zone separation

Material label	PA
Note on materials	RoHS-compliant
LABS (PWIS) conformity	VDMA24364-B1/B2-L


Operating and environmental conditions – Inscription labels for identifying the pressure zone separation

Ambient temperature	-5 ... 50°C
Storage temperature	-20 ... 70°C
Corrosion resistance class CRC ¹⁾	2 - Moderate corrosion stress

1) More information www.festo.com/x/topic/crc

Datasheet

General technical data – Inscription labels for label holders

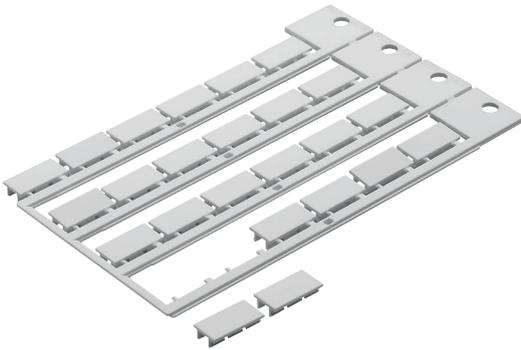

Size	5x5 mm	10x6 mm	15x6 mm	17x9 mm	20x8 mm	20x9 mm	23x4 mm
Height	5 mm	6 mm		9 mm	–	9 mm	–
Length	5 mm	10 mm	15 mm	17 mm	–	20 mm	–

Materials – Inscription labels for label holders


Size	5x5 mm	10x6 mm	15x6 mm	17x9 mm	20x8 mm	20x9 mm	23x4 mm
Material label	PA	–	PA	–			PC
Note on materials	RoHS-compliant						
LABS (PWIS) conformity	VDMA24364-B1/B2-L						
Fire test	UL94 V-2	–					

Operating and environmental conditions – Inscription labels for label holders

Size	5x5 mm	10x6 mm	15x6 mm	17x9 mm	20x8 mm	20x9 mm	23x4 mm
Corrosion resistance class CRC ¹⁾	0 - No corrosion stress						4 - Very high corrosion stress

1) More information www.festo.com/x/topic/crc

General technical data – Inscription labels for attaching to cables

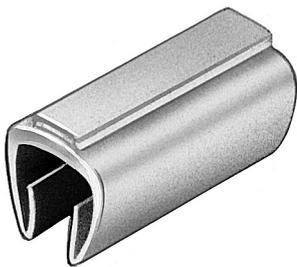

Length	20 mm
Height	5.2 mm

Materials – Inscription labels for attaching to cables

Note on materials	RoHS-compliant
LABS (PWIS) conformity	VDMA24364-B1/B2-L


Operation and environmental conditions – Inscription labels for attaching to cables

Corrosion resistance class CRC ¹⁾	0 - No corrosion stress
---	-------------------------

1) More information www.festo.com/x/topic/crc

Datasheet

General technical data – Inscription labels for solenoid valves

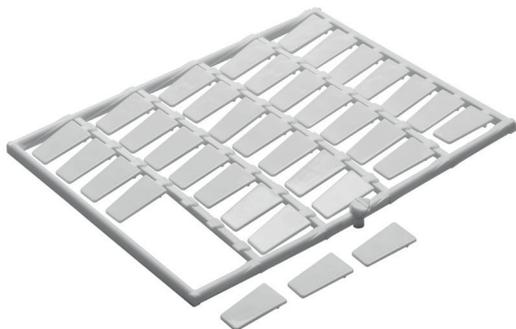

Short type code	ASLR	
Designation element	Inscription label holder	Inscription label
Design	–	Version X4
Labelling	–	Provided by the customer
Instructions on use	–	Printing on frame and as double sign possible
Type of mounting	–	Can be pressed in manually
Size	–	6 x 12.5 mm
Height	–	
Length	–	
Labelling area	–	4.9 mm x 11.4 mm
Labelling technology	–	Printer from PHOENIX CONTACT such as THERMOMARK, BLUEMARK or TOP-MARK
Designation element	–	Device and location identification, Individual mounting
Product weight	1 g	0.1 g

General technical data – Inscription labels for solenoid valves

Short type code	KMC/F/V	MH-BZ
Design	–	
Labelling	–	
Instructions on use	–	
Type of mounting	–	
Size	–	
Height	–	
Length	–	
Labelling area	–	
Labelling technology	–	
Designation element	–	
Product weight	–	7 g

Materials – Inscription labels for solenoid valves

Short type code	ASLR	
Designation element	Inscription label holder	Inscription label
Material label	–	PC
Material label holder	PP	–
Colour	–	White
Note on materials	RoHS-compliant	
LABS (PWIS) conformity	VDMA24364-B1/B2-L	VDMA24364-B2-L
Fire test	–	UL94 V-0

Datasheet

Materials – Inscription labels for solenoid valves

Short type code	KMC/F/V	MH-BZ
Material label	–	
Material label holder	–	
Colour	–	
Note on materials	–	
LABS (PWIS) conformity	VDMA24364-B2-L	VDMA24364-B1/B2-L
Fire test	–	

Operating and environmental conditions – Inscription labels for solenoid valves


Short type code	ASLR	
Designation element	Inscription label holder	Inscription label
Ambient temperature	–	-40 ... 85°C
Storage temperature	–	-40 ... 85°C
Corrosion resistance class CRC ¹⁾	2 - Moderate corrosion stress	–

1) More information www.festo.com/x/topic/crc

Operating and environmental conditions – Inscription labels for solenoid valves

Short type code	KMC/F/V	MH-BZ
Ambient temperature	–	
Storage temperature	–	
Corrosion resistance class CRC ¹⁾	–	

1) More information www.festo.com/x/topic/crc

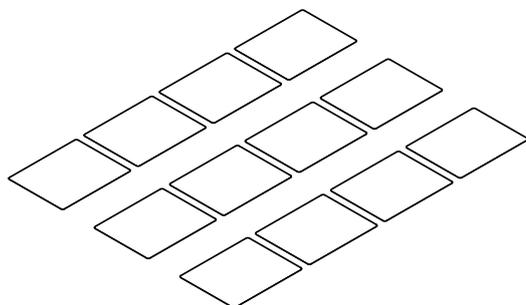General technical data – Inscription labels for sticking on

Size	12.5x6 mm
Length	12.5 mm
Height	6 mm

Materials – Inscription labels for sticking on

Note on materials	RoHS-compliant
LABS (PWIS) conformity	VDMA24364-B1/B2-L

Operating and environmental conditions – Inscription labels for sticking on

Corrosion resistance class CRC ¹⁾	0 - No corrosion stress
---	-------------------------

1) More information www.festo.com/x/topic/crc

Ordering data


Ordering data – Inscription labels for mechanically actuated valves					
	Size	Installation diameter	Labelling	Part no.	Type
	ø 22.3 mm	22.3 mm		4588	BZ-1-22
			OFF	4590	BZ-3-22
			ON	4589	BZ-2-22
			START	7814	BZ-7-22
	ø 30.5 mm	30.5 mm		9811	BZ-1-30
			OFF	9813	BZ-3-30
			ON	9812	BZ-2-30
	ø 90 mm	90 mm	EMERGENCY OFF	7821	BZ-7-30
				6527	BZ-6-22
				9815	BZ-6-30

Ordering data – Inscription labels for identifying the pressure zone separation					
	Labelling	Duct separation	Size of pack	Part no.	Type
		Zone separation, duct 3+5	5	8191743	ASLR-C-XA-TR
		Zone separation, duct 1+3+5		8191745	ASLR-C-XA-TS
		Zone separation, duct		8191742	ASLR-C-XA-TT

Ordering information – Inscription labels for label holders					
	Size	Size of pack	Part no.	Type	
	5x5 mm		574590	ASLR-L-55	
	10x6 mm		18576	IBS-6X10	
	15x6 mm	40	565306	ASLR-C-E4	
	17x9 mm	24	161937	IBS-9X17	
	20x8 mm	20	539388	IBS-8X20	
	20x9 mm		18182	IBS-9X20	
	23x4 mm	30	541598	ASLR-L-423	

Ordering data – Inscription labels for attaching to cables					
	Size	Instructions on use	Size of pack	Part no.	Type
	20x5.2 mm		1	33361	KM-BZ

Ordering data – Inscription labels for solenoid valves						
	Short type code	Designation element	Size of pack	Information about pack size	Part no.	Type
	ASLR	Inscription label holder			570818	ASLR-D-L1
		Inscription label	24	10 frames with 24 pieces each	8087174	ASLR-L-X4-612-P240
	KMC/FV				33362	KMC/FV-BZ-35X
	MH-BZ				197259	MH-BZ-80X

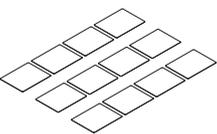Ordering information – Inscription labels for sticking on					
	Size	Size of pack	Part no.	Type	
	12.5x6 mm	24	8003303	ASLR-L-S6-2016	