

Mounting instructions click fittings NPKA


FESTO



Mounting instructions click fittings NPKA

Mounting and removal


Mounting

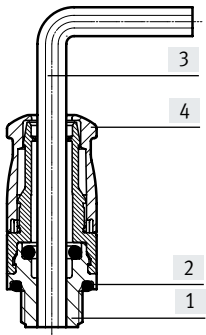

- [1] Screwed trunnion
- [2] Sealing ring
- [3] Allen key
- [4] Sleeve

- Screw the screwed plug and the sealing ring on to the counterpart and tighten in accordance with the nominal tightening torque.


- Special feature of the straight design NPKA-D: insert the long side of an Allen key completely into the click fitting through the sleeve. Use the entire contact surface of the internal hexagon.

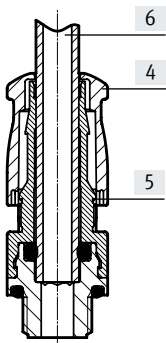

- [4] Sleeve
- [5] Stop contour 1
- [6] Plastic tubing

- Pull the sleeve as far as the stop contour 1 of the clamping collet, until you hear and feel the sleeve click in.

- Insert the plastic tubing through the open sleeve, clamping collet and tubing seal as far as the tube bearing shoulder.

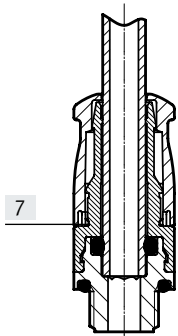

- [7] Stop contour 2

- Push the sleeve as far as the stop contour 2 of the clamping collet, until you hear and feel the sleeve click in.

- The closed sleeve pushes the clamping segment of the clamping collet against the plastic tubing, holding it in place.

Removal

In order to disassemble it, follow the steps in reverse order.