

FESTO

Quick Search Plus
Version 2024-02



Copyright © Festo AG & Co. KG

QuickSearchPlus

2024-02

Release Notes

Replace selected item in parts list

The screenshot shows the software interface with a toolbar at the top. A button labeled 'Replace' (marked with a '3') is being clicked. A dropdown menu is open, showing a list of parts with their designations and quantities. The part 'AEVUZ-80-10-P-A' (marked with a '2') is selected in the list. Below the toolbar, a table shows the current parts list with columns for Quantity, Part no., Type, Designation, and ID1. The part 'AEVUZ-80-20-P-A' (marked with a '1') is highlighted in the table.

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157246	AEVUZ-80-20-P-A	Compact air cylinder	AEVUZ-80-20-P-A
1	157306	FUA-80	Flange mounting	FUA-80

- 1 Select a line in the parts list
- 2 Choose the **new item** in the product list
- 3 Click the **Replace** button
- 4 The line is replaced by the **new item**

The screenshot shows the software interface after the replacement. The table below the toolbar now shows the updated parts list. The part 'AEVUZ-80-10-P-A' (marked with a '4') has replaced 'AEVUZ-80-20-P-A' in the table.

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157306	FUA-80	Flange mounting	FUA-80

Insert item after selected item in parts list

1

3

2

1

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157248	AEVUZ-100-10-P-A	Compact air cylinder	AEVUZ-100-10-P-A
1	157306	FUA-80	Flange mounting	FUA-80

- 1 Select a line in the parts list
- 2 Choose the **new item** in the product list
- 3 Click the **Insert** button
- 4 The **new item** is added **after** the selected line

4

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157248	AEVUZ-100-10-P-A	Compact air cylinder	AEVUZ-100-10-P-A
1	157306	FUA-80	Flange mounting	FUA-80

Insert items after selected item in parts list

3

Type	Part no.	Designation
> A	157248	AEVUZ-100-10-P-A Compact air cylinder
> A	157249	AEVUZ-100-15-P-A Compact air cylinder
> A	157250	AEVUZ-100-20-P-A Compact air cylinder
> A	157295	AEVUZ-100-15-P-A Compact air cylinder
> A	157244	AEVUZ-80-10-P-A Compact air cylinder
> A	157249	AEVUZ-100-15-P-A Compact air cylinder
> A	157296	AEVUZ-100-15-P-A Compact air cylinder
> A	157250	AEVUZ-100-20-P-A Compact air cylinder
> A	157297	AEVUZ-100-25-A-P-A Compact air cylinder

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157306	FUA-80	Flange mounting	FUA-80

1

- 1 Select a line in the parts list
- 2 Choose **new item** (hold down Shift or CTRL)
- 3 Click the **Insert** button
- 4 The **new items** added **after** the selected line

Quantity	Part no.	Type	Designation	ID1
1	549194	AKM-12	Cover cap	AKM-12
1	10399	AH-06-B	Toggle lever	AH-06-B
1	157244	AEVUZ-80-10-P-A	Compact air cylinder	AEVUZ-80-10-P-A
1	157248	AEVUZ-100-10-P-A	Compact air cylinder	AEVUZ-100-10-P-A
1	157249	AEVUZ-100-15-P-A	Compact air cylinder	AEVUZ-100-15-P-A
1	157250	AEVUZ-100-20-P-A	Compact air cylinder	AEVUZ-100-20-P-A
1	157306	FUA-80	Flange mounting	FUA-80

4

Online product data and QuickSearch product data are identical now

Online

Home > Products > Industrial automation > Tubes, fittings, plugs and cables > Pneumatic connection technology > Pneumatic fittings > Barbed fittings > CK > ACK-1/8-PK-6

Quick connector (designation)

ACK-1/8-PK-6 (Product tree)

7842

GTIN: 4052568020231

Pneumatic connection, port 1	Female thread G1/8
Pneumatic connection, port 2	For tubing outside diameter of 8 mm - For barbed fitting inside diameter of 6 mm with nut
Ambient temperature	-10 °C - 60 °C

Top features

- Industrial automation
 - Actuators
 - Motors and servo drives
 - Industrial robots
 - Vacuum technologies
 - Valves and valve technology
 - Sensors
 - Machine vision
 - Compressed air preparation
- Tubes, fittings, plugs and cables
 - Electrical connection technology
 - Pneumatic connection technology
 - Pneumatic tubing
 - Pneumatic fittings
 - Push-in fittings
 - Barbed fittings
 - Quick connector CK
 - Barbed fitting CN
 - Barbed hose fitting C-P N-P
 - Fitting NPCK

QS+

7842 **Quick connector**

ACK-1/8-PK-6

Shipping date UVP/RRP 81403 → Deliver!

Pneumatic connection, port 1	Female thread G1/8
Pneumatic connection, port 2	For tubing outside diameter of 8 mm For barbed fitting inside diameter of 6 mm with nut
Ambient temperature	-10 ... 60 °C

ACK-1/8-PK-6

Type	Part no.	Designation	PU
> ACK-1/4-PK-6	3712	Quick connector	10
> ACK-1/8-PK-3	5664	Quick connector	10
> ACK-1/8-PK-4	3714	Quick connector	10
> ACK-1/8-PK-6	7842	Quick connector	10

New Thai and Vietnamese
Removed Russian, Latvian, Lithuanian

All accessories and recommended accessories like online catalog

Find the perfect accessories to complete your product assembly

Filter by All Accessories Only recommended Accessories

Online

- Mounting accessories
- Function fittings
- Fittings
- Proximity sensors

Recommended accessories

Find the perfect accessories to complete your product assembly

Filter by All Accessories Only recommended Accessories

Online

- Mounting accessories
- Cylinder sensors for direct mounting
- Function fittings
- Other connectors
- Barbed fittings
- Quick connectors
- Push-in fittings

All accessories

DLGF-KF-25-150-PPSA	5072371	Linear actuator
Recommended Accessories		
DADG-HL-N8-P2	8069000	Cable holder
DAMH-L8-25-P-1	8069000	Profile mounting
DAYP-L8-25	8069000	Shock absorber ...
DYSS-8-8-Y1F	8069002	Pneumatic choc...
> GRLA-1/8-QS-6-D	★ 193144	One-way flow c...
> QS-G1/8-6	★ 186096	Push-in fitting
> QS-G1/8-6-I	★ 186107	Push-in fitting
> QSL-G1/8-6	★ 186117	Push-in L-fitting
> SDBT-MSX-1L-NU-E-0.3-N-M8	★ 8059123	Proximity sensor
> SDBT-MSX-1L-NU-E-2.5-N-LE	★ 8059124	Proximity sensor
> SDBT-MSX-1L-PU-E-0.3-N-M8	★ 8059120	Proximity sensor
> SDBT-MSX-1L-PU-E-2.5-N-LE	★ 8059121	Proximity sensor
> SMT-8M-A-NS-24V-E-0.3-M8D	★ 574339	Proximity sensor
> SMT-8M-A-NS-24V-E-2.5-OE	★ 574338	Proximity sensor
> SMT-8M-A-PS-24V-E-0.3-M8D	★ 574334	Proximity sensor
> SMT-8M-A-PS-24V-E-2.5-OE	★ 574335	Proximity sensor
> VFOE-LE-T-G18-Q6	★ 8068726	One-way flow c...
> Function fittings		
> Push-in fittings		
> Quick connectors		
> Other connectors		
> Barbed fittings		
> Mounting accessories		
> Cylinder sensors for direct mounting		

Takeover of **AdditionalInformation.txt** and **Filter.txt** information to **Fluiddraw**



8042559 - VUVG-BK10-M52-AT-F-1R8L-S Air solenoid valve Gewicht: 50 g (PK): 2.1.014 (ZA4) Zolltarifrnr.: 84812090 (DE) EUR 45,47

Close Product Finder Engineering New products History GTIN: 4052568286873 PL CE Kennzeichen: Copper-free: not Copper-free Kernprogramm: NO

ADREM INDUSTRIES

Products

- Industrial automation
 - Actuators and drives
 - Motors and servo drives
 - Handling systems and industrial robots
 - Vacuum technologies
- Pneumatic valves and valve manifolds
 - Directional control valves
 - ISO, CNOMO & NAMUR directional control
 - Universal directional control valves
 - Air solenoid valve, supplementary product
 - Basic valve LC LCB
 - Tiger Classic valve
 - Air solenoid valve VMPA
 - Air solenoid valve for individual connection
 - Solenoid valve for individual connection VUV
 - Plug-in solenoid valve VUVG
 - Plug-in solenoid valve VUVG-F1A
 - Air solenoid valve VUVS

4 products selected

Type	Part no.	Designation	PU	Gewicht	PG (FK)	Zolltarifrnr.:	EUR	PL	GTIN:	CE Kennzeichen:	Copper-free:	Kernp
> VUVG	564212	Air solenoid valve	1		2.1.011 (ZA4)	84812090 (DE)		Konfi...		nach EU-EMV...	not Copper-free	
> VUVG-BK10-B52-T-F-1H2L-S	8042556	Air solenoid valve	1	57 g	2.1.014 (ZA4)							
> VUVG-BK10-B52-T-F-1R8L-S	8042560	Air solenoid valve	1	50 g	2.1.014 (ZA4)							
> VUVG-BK10-M52-AT-F-1H2L-S	8042555	Air solenoid valve	1	45 g	2.1.014 (ZA4)							
> VUVG-BK10-M52-AT-F-1R8L-S	8042559	Air solenoid valve	1	50 g	2.1.014 (ZA4)							
> VUVG-BK10-T32C-AT-F-1H2L-S	8042554	Air solenoid valve	1	55 g	2.1.014 (ZA4)							
> VUVG-BK10-T32C-AT-F-1R8L-S	8042558	Air solenoid valve	1	55 g	2.1.014 (ZA4)							
> VUVG-BK14-B52-T-F-1H2L-S	8042572	Air solenoid valve	1	85 g	2.1.014 (ZA4)							
> VUVG-BK14-B52-T-F-1R8L-S	8042576	Air solenoid valve	1	85 g	2.1.014 (ZA4)							

Fluiddraw Copy CAD Compare products Show Online

Insert Products from List


Menge	Teilenummer	Proc	Ker	Typ	Verpackung	Artikl	Meng	Beleg	Gewicht:	Zolltarifrnr.:	GTIN:	CE Kennzeichen:	Kernprogramm:	LABS haltige Stoffe enthalten	Auswahl
1	8042559			VUVG-BK10-M52-AT-F...	1	Ma...	STK	VUV...	50 g	84812090 (DE)	4052568286873		NO	L	<input checked="" type="checkbox"/>
1	8042554			VUVG-BK10-T32C-AT-F...	1	Ma...	STK	VUV...	55 g	84812090 (DE)	4052568286835		NO	L	<input checked="" type="checkbox"/>
1	8042558			VUVG-BK10-T32C-AT-F...	1	Ma...	STK	VUV...	55 g	84812090 (DE)	4052568286866		NO	L	<input checked="" type="checkbox"/>
1	8042572			VUVG-BK14-B52-T-F-1...	1	Ma...	STK	VUV...	85 g	84812090 (DE)	4052568286972		NO	L	<input checked="" type="checkbox"/>

OK Cancel

Fluiddraw

VUVG-BK10-M52-AT-F-1R8L-S VUVG-BK10-T32C-AT-F-1H2L-S VUVG-BK10-T32C-AT-F-1R8L-S VUVG-BK14-B52-T-F-1H2L-S

Id. Nr.	Stück	Kennzeichnung	Teilenummer	Typ	Artikelbenennung	Gewicht:	GTIN:	Zolltarifrnr.:
1	1	-QM2	8031518	VUVG-B14-T...	Magnetventil	80 g	4052568286817	84812090 (DE)
2	1	-QM6	8042559	VUVG-BK10-...	Magnetventil	50 g	4052568286873	84812090 (DE)
3	1	-QM7	8042554	VUVG-BK10-...	Magnetventil	55 g	4052568286835	84812090 (DE)
4	1	-QM8	8042558	VUVG-BK10-...	Magnetventil	55 g	4052568286866	84812090 (DE)
5	1	-QM9	8042572	VUVG-BK14-...	Magnetventil	85 g	4052568286972	84812090 (DE)

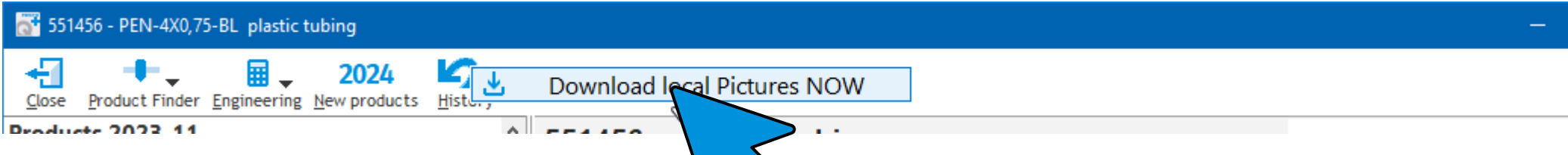

FESTO

Small product thumbnail as **photo** (no black and white line drawing like before) Click this button to see

551456 - PEN-4X0,75-BL plastic tubing

2023-11

551456 plastic tubing
PEN-4X0,75-BL

Shipping date \$UVP/RRP 81403 → Deliver!

PEN-4X0,75-BL

Type	Part no.	Designation	PU
→	PEN-4X0,75-BL	551456 plastic tubing	50
→	PEN-4X0,75-BL-500	551444 plastic tubing	500
→	PEN-4X0,75-GE	551480 plastic tubing	50
→	PEN-4X0,75-GN	551468 plastic tubing	50
→	PEN-4X0,75-NT	543246 plastic tubing	50
→	PEN-4X0,75-RT	551474 plastic tubing	50
→	PEN-4X0,75-SI	551462 plastic tubing	50
→	PEN-4X0,75-SI-500	551450 plastic tubing	500
→	PEN-4X0,75-SW	543240 plastic tubing	50
→	PEN-4X0,75-SW-500	551438 plastic tubing	500
→	PEN-6X1-BL	551457 plastic tubing	50
→	PEN-6X1-BL-500	551445 plastic tubing	500
→	PEN-6X1-GE	551481 plastic tubing	50
→	PEN-6X1-GN	551469 plastic tubing	50
→	PEN-6X1-NT	543247 plastic tubing	50
→	PEN-6X1-RT	551475 plastic tubing	50
→	PEN-6X1-SI	551463 plastic tubing	50
→	PEN-6X1-SI-500	551451 plastic tubing	500
→	PEN-6X1-SW	543241 plastic tubing	50
→	PEN-6X1-SW-500	551439 plastic tubing	500
→	PEN-8X1,25-BL	551458 plastic tubing	50
→	PEN-8X1,25-BL-400	551446 plastic tubing	400
→	PEN-8X1,25-GE	551482 plastic tubing	50
→	PEN-8X1,25-GN	551470 plastic tubing	50
→	PEN-8X1,25-NT	543248 plastic tubing	50

551456 - PEN-4X0,75-BL Plastic tubing


2024-01

551456 Plastic tubing
PEN-4X0,75-BL

Shipping date \$UVP/RRP 81403 → Deliver!

PEN-4X0,75-BL

Type	Part no.	Designation	PU
→	PEN-4X0,75-BL	551456 Plastic tubing	50
→	PEN-4X0,75-BL-500	551444 Plastic tubing	500
→	PEN-4X0,75-GE	551480 Plastic tubing	50
→	PEN-4X0,75-GN	551468 Plastic tubing	50
→	PEN-4X0,75-NT	543246 Plastic tubing	50
→	PEN-4X0,75-RT	551474 Plastic tubing	50
→	PEN-4X0,75-SI	551462 Plastic tubing	50
→	PEN-4X0,75-SI-500	551450 Plastic tubing	500
→	PEN-4X0,75-SW	543240 Plastic tubing	50
→	PEN-4X0,75-SW-500	551438 Plastic tubing	500
→	PEN-6X1-BL	551457 Plastic tubing	50
→	PEN-6X1-BL-500	551445 Plastic tubing	500
→	PEN-6X1-GE	551481 Plastic tubing	50
→	PEN-6X1-GN	551469 Plastic tubing	50
→	PEN-6X1-NT	543247 Plastic tubing	50
→	PEN-6X1-RT	551475 Plastic tubing	50
→	PEN-6X1-SI	551463 Plastic tubing	50
→	PEN-6X1-SI-500	551451 Plastic tubing	500
→	PEN-6X1-SW	543241 Plastic tubing	50
→	PEN-6X1-SW-500	551439 Plastic tubing	500
→	PEN-8X1,25-BL	551458 Plastic tubing	50
→	PEN-8X1,25-BL-400	551446 Plastic tubing	400
→	PEN-8X1,25-GE	551482 Plastic tubing	50
→	PEN-8X1,25-GN	551470 Plastic tubing	50
→	PEN-8X1,25-NT	543248 Plastic tubing	50

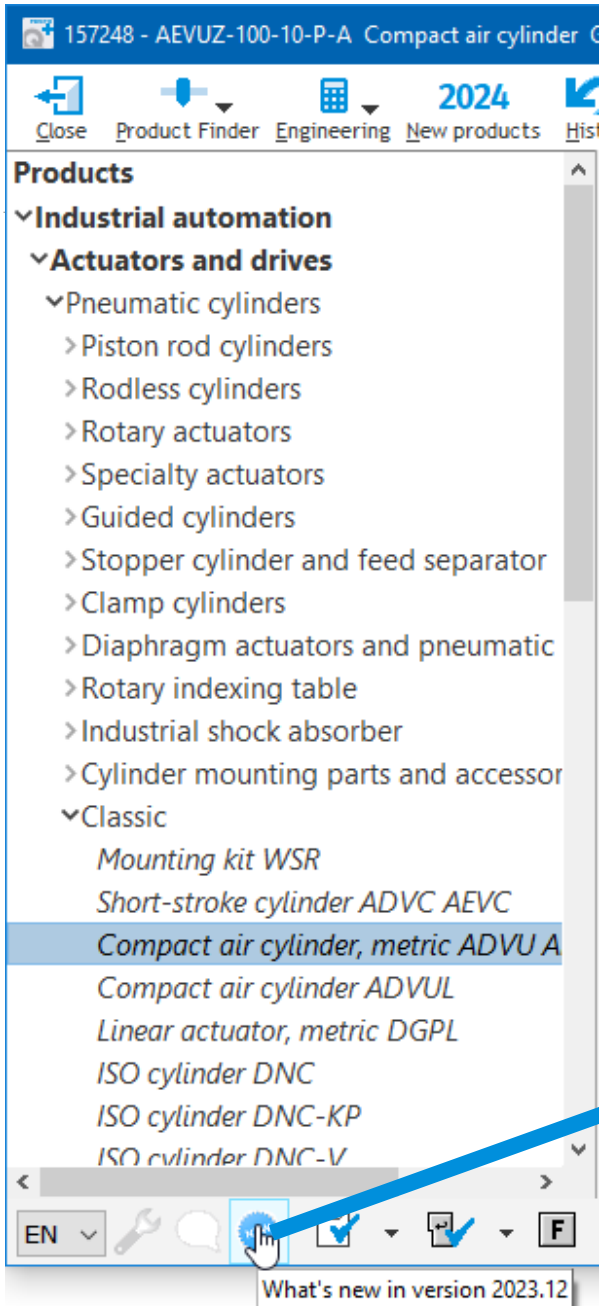

Button **What is new in version xxx**





bugs fixes and minor improvements

Short description

Fix column width when **copy parts list to Online-Outlook** in Browser

When moving mouse on tiny product thumbnail, product picture turned white

Removed unit conversion tool from internal SPIMS+ menu (tool no more available)

Fixed an issue with phased-out MS4- and MS6- products which are part of KMAT now