

FESTO

Quick Search Plus
Version 2024-05



Copyright © Festo AG & Co. KG

QuickSearchPlus

2024-05

Release Notes

Insert item above selected item in parts list

1

3

2

Quantity	Part ...	Type	Designation	Str...	Re..
1	175...	GRLA-M3	One-way flow cont...		
1	187...	MPPES-3-1/4-...	Proportional-press..		
1	13989	PZVT-99999-...	Timer		

1

- 1 Select a line in the parts list
- 2 Choose the **new item** in the product list
- 3 Click the **Insert** button
- 4 The **new item** is added **above** the selected line

Quantity	Part no.	Type	Designation	I
1	175038	GRLA-M3	One-way flow control valve	G
1	30649	S-3-BE-SW	Micro switch	S
1	187333	MPPES-3-1/4-10-010	Proportional-pressure r	4
1	13989	PZVT-99999-MIN-B	Timer	P

Insert items above selected item in parts list

3

Insert

Type	Part no.	Designation
30648 S-3-BE	30648	Micro switch
30649 S-3-BE-SW	30649	Micro switch
7843 S-3-PK-3-B	7843	Micro stem actuated valve
52432	52432	Roller lever valve
9694	9694	Pneumatic limit val...
30648	30648	Micro switch
30649	30649	Micro switch
7843	7843	Micro stem actuate...
8069031	8069031	Protective hood
8184143	8184143	Impact protection
8035560	8035560	Protective hood

2

Quantity	Part no.	Type	Designation	ID1
1	175038	GRLA-M3	One-way flow control valve	GR
1	30649	S-3-BE-SW	Micro switch	S-
1	13989	PZVT-99999-MIN-B	Timer	PZ

1

- 1 Select a line in the parts list
- 2 Choose **new items** (hold down Shift or CTRL)
- 3 Click the **Insert .. above** button
- 4 The **new items** added **above** the selected line




Quantity	Part no.	Type	Designation	ID1
1	175038	GRLA-M3	One-way flow control valve	GR
1	30648	S-3-BE	Micro switch	S-3
1	30649	S-3-BE-SW	Micro switch	S-3
1	7843	S-3-PK-3-B	Micro stem actuated valve	S-3
1	30649	S-3-BE-SW	Micro switch	S-3
1	13989	PZVT-99999-MIN-B	Timer	PZ

4







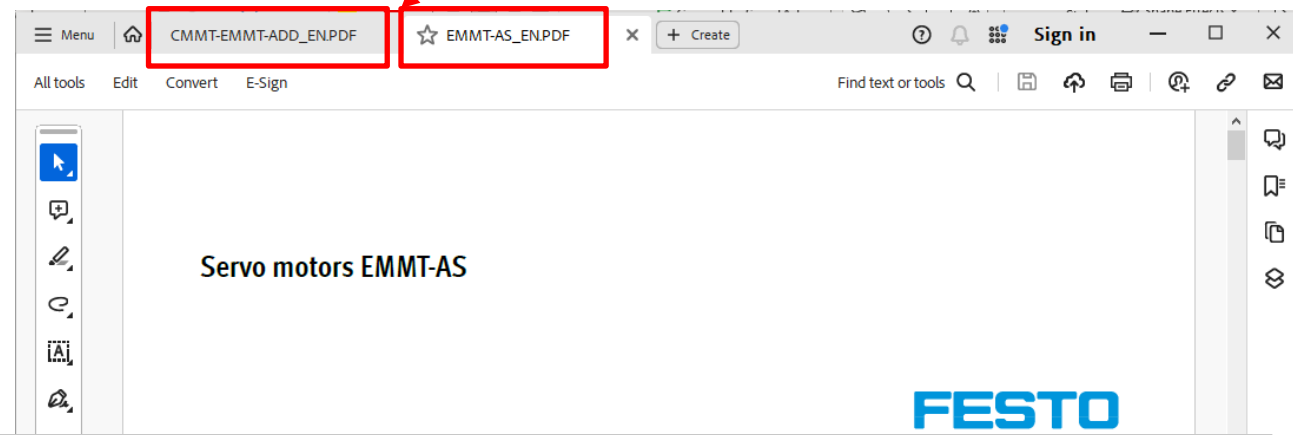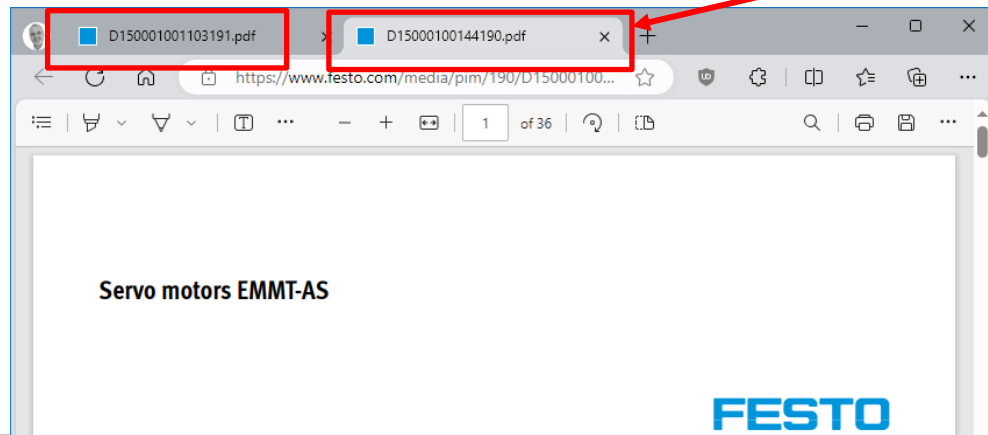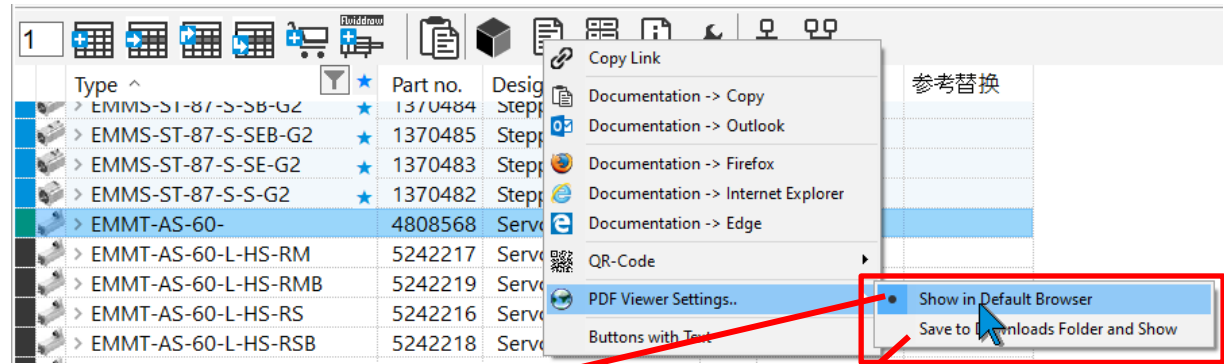



New selection to view catalog PDF – **Show PDF in Acrobat** and no **Dxxx.PDF** name anymore

PDFs in Browser are shown with a Dxxxx.PDF file name.












With the new setting **Save to Downloads Folder and Show** the documents are downloaded first and opened in Acrobat



Positioning of pictures and symbols in Excel export improved (reported by Jurgen)

A	B	C	D	E	F
		Photo	Quanti	Part no.	ID1
1					
2					
3	1		4	8082408	ELCC-TB-KF-90-2000-0H
4	2		2	5255537	EMMT-AS-100-L-HS-
5	3			8081061	DASI-E21-90/110-S
6	4		4	8081060	DASI-E21-90-S8-9
7	5		4	8067062	DAYP-E21-90
8	6		2	8082459	DHAA-R-E21-70...110-F
9	7		4	160274	YSR-32-60-C
10	8		8	150391	SIEN-M8B-PO-S
11	9		4	556815	EGC-120-2000-TB-KF-
12	10		24	558044	MUE-120/185

2024-02

A	B	C	D	E	F	G	H
	Photo	Quanti	Part no.	ID1	Designation		
1		4	8082408	ELCC-TB-KF-90-2000-0H-P0-CR	Cantilever axis		
2		2			motor		
3		8			ch lug		
4		4			or bracket		
5		4			k absorber		
6		2			ter kit		
7		4			k absorber		
8		8			imity sens		
9		4			hed belt a:		
10		24			le mountli		
11		2	555733	EMMT-AS-100-M-HS-RMB	Servo motor		
12		8	551392	SIES-8M-PO-24V-K-0,3-M8D	Proximity sens		



2024-05



bugs fixes and minor improvements

Short description

VTUC-EX configurator start without error message

Right-click copy on part no/type/description for C-codes now shows C-code

Valid KMAT codes shown as incorrect e.g. DSNU-32-60-PPS-A

DFM-12-...-B (529119) and DFM-16-...-B (529120) show a x-length, not as configurable products

Action “CAD on Function key” not working

Picture quality in Outlook mail are not as good as in 2023-11 version