


# DUO plastic tubing PU-3-DUO-BS

Part number: 11958

FESTO

For CN and CK connectors, particularly flexible and kink-resistant, polyurethane (not approved for use in the food industry).  
The maximum pressure value is permissible at the maximum temperature.

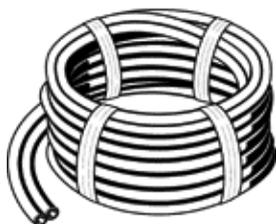

## Data sheet

Feature	Value
Outside diameter	4.4 mm
Bending radius relevant for flow rate	14 mm
Inside diameter	2.9 mm
Temperature dependent operating pressure	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Ambient temperature	-35 ... 60 °C
Authorisation	TÜV
Product weight according to length	0.0192 kg/m
Colour	blue/black
Shore hardness	D 52 +/-3
Materials note	Free of copper and PTFE
Materials information for tubing	TPE-U(PU)