


# coupling

## EAMC-40-66-19-20

Part number: 123847

FESTO

For electromechanical drive with servomotor

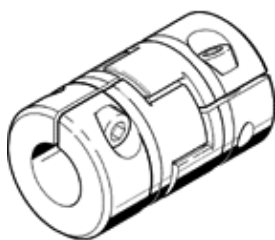

## Data sheet

| Feature                | Value                  |
|------------------------|------------------------|
| Holder diameter 1      | 19 mm                  |
| Holder diameter 2      | 20 mm                  |
| Size                   | 40                     |
| Nominal length         | 66 mm                  |
| Assembly position      | Any                    |
| Max. speed             | 6,500 1/min            |
| Storage temperature    | -25 ... 60 °C          |
| Relative air humidity  | 0 - 95 %               |
| Ambient temperature    | -25 ... 60 °C          |
| Mass moment of inertia | 42.3 kgmm <sup>2</sup> |
| Transferable torque    | 21 Nm                  |
| Product weight         | 139 g                  |
| Materials note         | Conforms to RoHS       |