 



# Pneumatic valve VLHE-3-3/8

Part number: 12909

FESTO

Normally closed, slow start-up valve, for use individually or in conjunction with S-series service units.

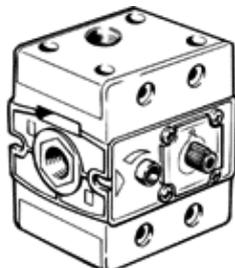

## Data sheet

Feature	Value
Design structure	Poppet seat
Sealing principle	soft
Exhaust-air function	throttleable
Manual override	Pushing
Valve function	3/2 closed, monostable
Operating pressure	2 ... 12 bar
Standard nominal flow rate	2,100 l/min
Switching time off	19.5 ms
Switching time on	8.5 ms
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Mounting type	with through hole
Assembly position	Any
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 2	G3/8
Pneumatic connection, port 3	G3/8
Nominal size	9 mm