

 

Solenoid valve

MFHE-3-1/4-B

Part number: 14329

FESTO

On-off valve for delayed pressure build-up, with manual override.
Solenoid coil and plug socket not included.

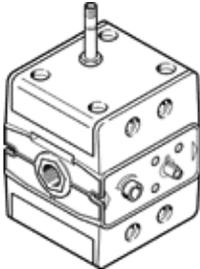

Data sheet

Feature	Value
Design structure	Poppet seat
Flow direction	non reversible
Sealing principle	soft
Exhaust-air function	not throttleable
Type of reset	mechanical spring
Type of piloting	direct
Valve function	3/2 closed, monostable
Operating pressure	2 ... 10 bar
Standard nominal flow rate	1,200 l/min
Switching time off	80 ms
Switching time on	12 ms
Materials note	Conforms to RoHS
Medium temperature	-10 ... 60 °C
Ambient temperature	-5 ... 40 °C
Mounting type	with through hole
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	G1/4
Pneumatic connection, port 3	G1/4
Nominal size	8 mm