


Coupling
EAMC-40-66-12-14
Part number: 1452803

FESTO

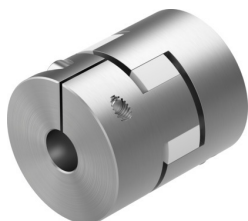

Data sheet

Feature	Value
Mounting diameter 1	12 mm
Mounting diameter 2	14 mm
Size	40
Nominal length	66 mm
Mounting position	optional
Max. rotational speed	6500 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Ambient temperature	-25 °C...60 °C
Mass moment of inertia	42.3 kgmm ²
Transmittable torque	21 Nm
Product weight	139 g
Note on materials	RoHS-compliant