


Standard cylinder DNG-3"-2"-PPV-A

Part number: 151622

FESTO

Based on ISO 15552, NF E 49 003.1 and UNI 10 290, For proximity sensing, with adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.

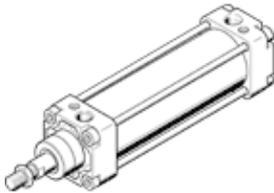

Data sheet

Feature	Value
Stroke	50.8 mm
Piston diameter	80 mm
Piston rod thread	UNF3/4-16
Cushioning	Pneumatic cushioning, adjustable at both ends (PPV)
Conforms to standard	ISO 6431 VDMA 24562
Piston-rod end	Male thread
Operating pressure	0.6 ... 10 bar
Mode of operation	double-acting
Ambient temperature	-20 ... 80 °C
Cushioning length	36 mm
Theoretical force at 6 bar, return stroke	2,721 N
Theoretical force at 6 bar, advance stroke	3,016 N
Pneumatic connection	M10