

 

Air reservoir

VZS-10-B

Part number: 151923

FESTO

To EU Directive 87/404/EEC and EN 286-1:1998.
Products to be discontinued. Available until 2011.

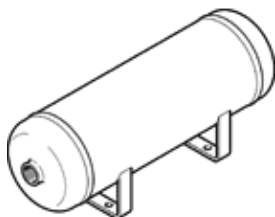

Data sheet

| Feature | Value |
|---|-------------------------------------|
| Volume | 10 l |
| Assembly position | Downward condensate drain |
| Conforms to standard | EN 286-1 |
| Operating pressure | -0.95 ... 16 bar |
| Operating medium | Nitrogen Compressed air |
| CE mark (see declaration of conformity) | to EU directive pressure reservoirs |
| Corrosion resistance classification CRC | 4 |
| Medium temperature | -10 ... 100 °C |
| Ambient temperature | -10 ... 100 °C |
| Authorisation | TÜV |
| Max. tightening torque, connecting thread | 130 Nm |
| Max. tightening torque, condensate drain | 27 Nm |
| Product weight | 6,000 g |
| Mounting type | with through hole |
| Condensate drain connection | G3/8 |
| Pneumatic connection | G1 |
| Materials note | Free of copper and PTFE |
| Material information, air reservoir | Steel Painted |