


 
# Linear drive DGPL-11/16"- -PPV-A-GF-B

Part number: 162931

FESTO

For proximity sensing, rodless, with positive-locking connection between piston and driver and adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.

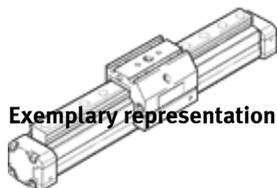

Exemplary representation

## Data sheet

Feature	Value
Stroke	10 ... 3,000 mm
Piston diameter	11/16"
Cushioning	PPV: Pneumatic cushioning adjustable at both ends YXR: Shock absorber, hard characteristic curve
Guide	Plain-bearing guide
Driver principle	positive-locking (slot)
Operating pressure	2 ... 8 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Ambient temperature	-10 ... 60 °C
Cushioning length	16 mm
Pneumatic connection	UNF10-32