


# connecting cable KVIA-5

Part number: 163960

FESTO

For analogue units.

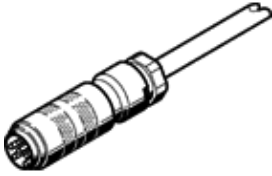

## Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	$\leq 250$ V
Permissible current load	1 A
Protection class	IP65
Ambient temperature	-30 ... 80 °C
Product weight	306 g
Electrical connection	Plug straight
Cable structure	6x0,25
Cable diameter	8 mm
Cable length	5 m
Mounting type	With sleeve nut
Materials information, housing	PBT
Materials information, cable sheaths	PVC
Material information for crimp connectors	Bronze Silver and gold plated