


Power supply SPC200-PWR-AIF

Part number: 170175

FESTO

With power supply and axis interface.

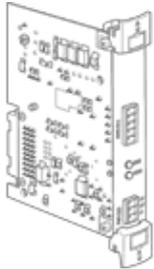

Data sheet

Feature	Value
Max. current consumption, load	5 A
Max. current consumption, logic	4 A
Nominal operating voltage DC	24 V
Power failure buffering for logic voltage	10 ms
Residual ripple	2 %
Typical current consumption, plug-in module	100 mA
Permissible voltage fluctuation	-5 % / +25 %
Product weight	82 g
Electrical connection, operating voltage	Terminal strip 3-pin
Electrical connection, AIF OUT	5-pin
Performance feature, axis connection	2 pneumatic axes Max. 16 digital function inputs Max. 16 digital function outputs
Installation space	1