


Axis interface SPC-AIF-MTS

Part number: 170231

FESTO

For Temposonics/AIF or DGPI/L-AIF.

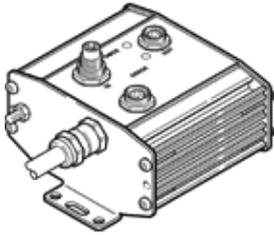

Data sheet

| Feature | Value |
|--|---|
| Max. proportional valve current consumption | 1.1 A |
| Typical axis interface current consumption | 200 mA |
| CE mark (see declaration of conformity) | to EU directive for EMC |
| Continuous shock resistance per DIN/IEC 68, parts 2 - 82 | Tested in accordance with severity level 2 |
| Protection class | IP65 to IEC 60529 |
| Vibration resistance per DIN/IEC 68, parts 2 - 6 | Tested in accordance with severity level 2 |
| Ambient temperature | 0 ... 50 °C |
| Product weight | 300 g |
| Electrical connection, proportional valve | Plug Round design M9 7-pin |
| Electrical connection, displacement encoder | 6-pin Cable with plug Per DIN 45322 Round design |
| Electrical connection, AIF IN | Plug Round design M9 5-pin |
| Electrical connection, AIF OUT | Plug socket Round design M9 5-pin |
| Cable length | 0.3 m |