

service unit

FRC-1-D-7-MAXI-NPT

 

Part number: 173890

Classic - do not use for new projects

Filter/regulator/lubricator combination, maximum outlet pressure 7 bar, 40 µm filter, with metal bowl guard. With manual condensate drain.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

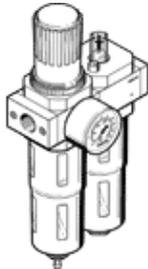

Data sheet

Feature	Value
Size	Maxi
Assembly position	Vertical
Condensate drain	manual rotary
Grade of filtration	40 µm
Operating pressure	1 ... 16 bar
Standard nominal flow rate	8,700 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	2,520 g
Mounting type	Line installation With mounting bracket Optional
Pneumatic connection, port 1	1 NPT
Pneumatic connection, port 2	1 NPT
Material housing	Zinc die-casting
Material bowl	PC