


Swivel flange SNCS-50

Part number: 174399

FESTO

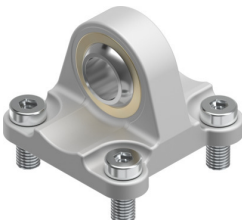

Data sheet

Feature	Value
Size	50
Based on standard	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C...150 °C
Max. load capacity	2.5 kN
Product weight	216 g
Note on materials	RoHS-compliant
Material mounting	Die-cast aluminium
Material rod end bearing	Steel PTFE
Material screws	Steel Galvanised