


# Connecting cable KMP1-02-II-16-5

Part number: 175662  
Product to be discontinued

FESTO

For valve terminal IIMP-02, fully assembled for 16 valve positions, 5 m long  
Type to be discontinued. Available until 2017. See Support Portal for alternative products.

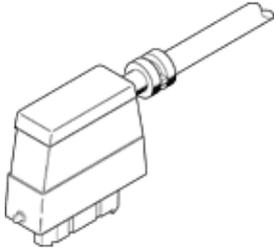

## Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	≤ 300 V
Operating voltage range DC	≤ 250 V
Permissible current load	4 A
Protection class	IP65
Ambient temperature with flexible cable installation	5 ... 70 °C
Ambient temperature	-30 ... 70 °C
Product weight	5,326 g
Electrical connection	72-pin Plug socket
Cable structure	80 x 0,75 mm <sup>2</sup>
Cable diameter	24 mm
Cable length	5 m
Mounting type	With clamp strap
Materials information, housing	Die-cast light alloy
Materials information, cable sheaths	PE
Material information for crimp connectors	Copper alloy Silver plated