


# manifold block VIGI-04-D-3

Part number: 18841  
Product to be discontinued

FESTO

[For valve terminal](#)

Type to be discontinued. Available until 2026. See Support Portal for alternative products.

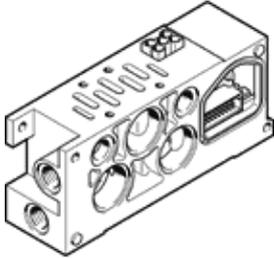

## Data sheet

Feature	Value
Based on the standard	ISO 5599-2
Max. number of valve positions	1
Operating pressure	-0.9 ... 16 bar
Authorisation	UL - Recognized (OL)
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 60 °C
Protection class	IP65
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Pneumatic connection, port 1	G1
Pneumatic connection, port 2	G1/2
Pneumatic connection, port 3	G1
Pneumatic connection, port 4	G1/2
Pneumatic connection, port 5	G1
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium die cast