


# End plate IEPR-04-D-2

Part number: 18878

FESTO

For valve terminal

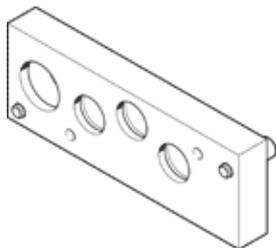

## Data sheet

Feature	Value
Operating pressure	-0.9 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Medium temperature	-10 ... 60 °C
Protection class	IP65
Ambient temperature	-10 ... 60 °C
Authorisation	UL - Recognized (OL)
Mounting method for sub-base	with internal (female) thread
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 3	G3/4
Pneumatic connection, port 5	G3/4