


Power supply module VABF-C8-12-P3A5-QX

Part number: 1894888

FESTO

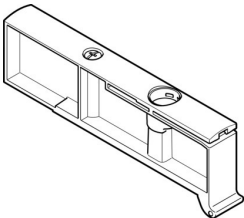

Data sheet

Feature	Value
Operating pressure	8 bar
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-5 °C...60 °C
Ambient temperature	-5 °C...60 °C
Product weight	13.8 g
Pneumatic connection, port 1	Prepared for cartridge
Note on materials	RoHS-compliant
Material housing	PA-reinforced