


Suction cup without connector ESV-20-CS

Part number: 191072

FESTO

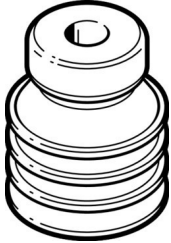

Data sheet

Feature	Value
Height compensator for suction cup	7 mm
Min. workpiece radius	50 mm
Suction cup diameter	20 mm
Suction cup volume	2.75 cm ³
Position of connection	Top
Mounting position	optional
Suction cup shape	Round bellows 3.5 convolutions
Operating pressure	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Nominal operating pressure	-70 kPa -0.7 bar -10.15 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 zone III
Suitable for use with food	See supplementary material information
Ambient temperature	-30 °C...180 °C
Holding force at nominal operating pressure	8.2 N
Product weight	2.1 g
Colour	Transparent
Shore hardness	50 +/- 5
Note on materials	RoHS-compliant
Material suction cup	VMQ (silicone)