 



Air reservoir VZS-5-B

Part number: 192160

FESTO

To EU Directive 87/404/EEC and EN 286-1:1998.
Products to be discontinued. Available until 2011.

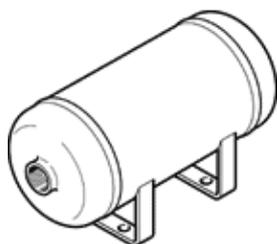

Data sheet

Feature	Value
Volume	5 l
Assembly position	Downward condensate drain
Conforms to standard	EN 286-1
Operating pressure	-0.95 ... 16 bar
Operating medium	Nitrogen Compressed air
CE mark (see declaration of conformity)	to EU directive pressure reservoirs
Corrosion resistance classification CRC	4
Medium temperature	-10 ... 100 °C
Ambient temperature	-10 ... 100 °C
Authorisation	TÜV
Max. tightening torque, connecting thread	130 Nm
Max. tightening torque, condensate drain	27 Nm
Product weight	3,500 g
Mounting type	with through hole
Condensate drain connection	G3/8
Pneumatic connection	G1
Materials note	Free of copper and PTFE
Material information, air reservoir	Steel Painted