


Service unit combination LFR-3/4-D-DI-MAXI-KF

Part number: 192452

FESTO

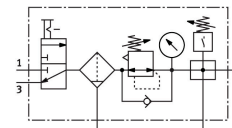

Data sheet

Feature	Value
Size	Maxi
Series	D
Actuator lock	Rotary knob with detent
Mounting position	Vertical $\pm 5^\circ$
Grade of filtration	40 μm
Condensate drain	Manually rotating
Design	Branching module Pressure switch On/off valve Filter regulator with pressure gauge
Max. condensate volume	43 cm^3
Bowl guard	Metal bowl guard
Pressure gauge (ANALOG) or Pressure display (DIGITAL)	With pressure gauge
Operating pressure	0.1 MPa...1.6 MPa 1 bar...16 bar 14.5 psi...232 psi
Pressure regulation range	0.05 MPa...1.2 MPa 0.5 bar...12 bar 7.25 psi...174 psi
Standard nominal flow rate (standardised to DIN 1343)	6000 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [-:~:] Inert gases
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Air purity class at output	Compressed air to ISO 8573-1:2010 [6:8:4] Inert gases
Media temperature	-10 $^\circ\text{C}$...60 $^\circ\text{C}$
Ambient temperature	-10 $^\circ\text{C}$...60 $^\circ\text{C}$
Product weight	3500 g
Type of mounting	In-line installation With accessories Either:
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G3/4

Feature	Value
Material housing	Die-cast zinc
Material bowl	PC