


Lubricator
LOE-D-MAXI
Part number: 192577

FESTO

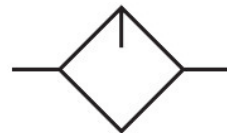

Data sheet

Feature	Value
Size	Maxi
Series	D
Mounting position	Vertical +/-5°
Design	Proportional standard mist lubricator
Max. oil capacity	190 cm ³
Bowl guard	Metal bowl guard
Operating pressure	0 MPa...1.6 MPa 0 bar...16 bar 0 psi...232 psi
Min. flow rate for lubricator function	10 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C...60 °C
Air purity class at output	Compressed air to ISO 8573-1:2010 [7:4:-] Inert gases
Media temperature	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Product weight	1100 g
Type of mounting	With accessories
Note on materials	RoHS-compliant
Material bowl	PC