


Shut-off valve HE-N3/4-LO

Part number: 197131

FESTO

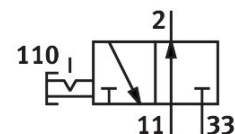

Data sheet

Feature	Value
Sealing principle	Soft
Exhaust-air function	Without flow control option
Type of piloting	Direct
Operating pressure	1 bar...10 bar
C value	36.28 l/sbar
b value	0.21
Standard nominal flow rate (standardised to DIN 1343)	8000 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-10 °C...60 °C
Ambient temperature	-10 °C...60 °C
Type of mounting	Screw-in
Mounting position	optional
Flow direction	Non-reversible
Product weight	1000 g
Pneumatic connection, port 1	3/4 NPT
Pneumatic connection, port 2	3/4 NPT
Pneumatic connection, port 3	1 NPT
Material seals	NBR TPE-U(PU)
Material housing	Die-cast aluminium